


- For linking or closing chains
- White chromed steel
- Low cost range, no SWL specified
- Engraved with ring diameter

### Application


- Nominal load figures are given as an indication only
- Should not be used for lifting (load values not guaranteed)

### Info

- Also available in stainless steel

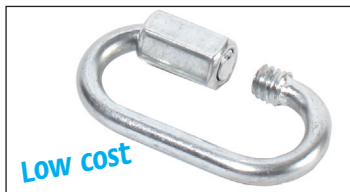

**NEW!**

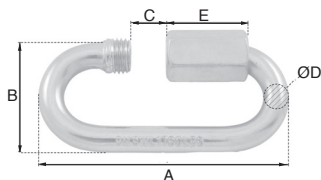

### DISCOUNTS

Qty	1+	20+	40+	60+	80+	100+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	ØD	A	B	C	E	Nominal load (kg)	Weight (g)	Price each 1 to 19
MRA1-03/ECO	3,5	36	18	5,0	12	100	8	0,45 €
MRA1-04/ECO	4,0	41	20	6,0	14	180	12	0,55 €
MRA1-05/ECO	5,0	51	24	7,7	17	280	22	0,61 €
MRA1-06/ECO	6,0	59	27	8,5	21	400	36	0,73 €
MRA1-07/ECO	7,0	68	31	9,6	22	550	52	0,97 €
MRA1-08/ECO	8,0	74	34	10,4	24	700	76	1,13 €
MRA1-09/ECO	9,0	82	39	12,0	27	900	110	1,56 €
MRA1-10/ECO	10,0	90	42	13,5	30	1100	146	2,05 €
MRA1-12/ECO	12,0	106	48	14,8	34	1500	234	3,15 €
MRA1-14/ECO	14,0	122	56	15,5	40	2200	358	6,24 €
MRA1-16/ECO	16,0	141	63	17,5	44	2900	520	10,12 €

## Altri prodotti...



NCT  
Giunto di collegamento, Ad angolo fisso



HTD5M\_15  
Puleggia dentata di trasmissione tipo HTD, HTD5 Acciaio



YG4  
Ingranaggio dritto PRESTAZIONE, Acciaio 35NCD6



LVT  
Mini martinetto motorizzato 2A, 2 ampere



RURp  
Rotella girevole con piastra, Poliuretano - Mozzo alluminio (Ultra S...



SLH-M  
Dado per bloccaggio a leva, Dado con estremità sferica




BTCW  
Tappo inox per tubo quadrato, A saldare



GLP  
Volantino a 6 lobi, Tecnoaluminio - Acciaio



ZBRA  
Ingranaggio conico in plastica, 1:1

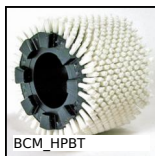

BCM\_HPBT  
Spazzola cilindrica modulare, Filo poliestere PBT




DOMI80  
Kit di raccordo, Kit di raccordo XY



HRV  
Sistema di guida su binario a V Simple Select®, Binario con carrello

## Prodotti correlati

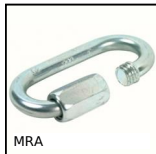

MRA  
Maglia rapida, Acciaio



FCHN\_CHNSS  
Catena dritta a maglie lunghe, Acciaio zincato