


- For linking or closing chains
- White chromed steel
- Low cost range, no SWL specified
- Engraved with ring diameter

Application


- Nominal load figures are given as an indication only
- Should not be used for lifting (load values not guaranteed)

Info

- Also available in stainless steel

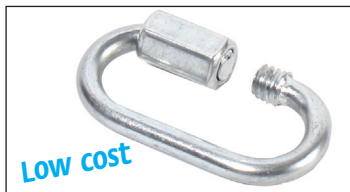

NEW!

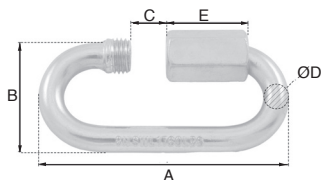

DISCOUNTS

Qty	1+	20+	40+	60+	80+	100+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	ØD	A	B	C	E	Nominal load (kg)	Weight (g)	Price each 1 to 19
MRA1-03/ECO	3,5	36	18	5,0	12	100	8	0,45 €
MRA1-04/ECO	4,0	41	20	6,0	14	180	12	0,55 €
MRA1-05/ECO	5,0	51	24	7,7	17	280	22	0,61 €
MRA1-06/ECO	6,0	59	27	8,5	21	400	36	0,73 €
MRA1-07/ECO	7,0	68	31	9,6	22	550	52	0,97 €
MRA1-08/ECO	8,0	74	34	10,4	24	700	76	1,13 €
MRA1-09/ECO	9,0	82	39	12,0	27	900	110	1,56 €
MRA1-10/ECO	10,0	90	42	13,5	30	1100	146	2,05 €
MRA1-12/ECO	12,0	106	48	14,8	34	1500	234	3,15 €
MRA1-14/ECO	14,0	122	56	15,5	40	2200	358	6,24 €
MRA1-16/ECO	16,0	141	63	17,5	44	2900	520	10,12 €

Altri prodotti...



MO

Coppia ruota e vite senza fine , Acciaio temprato



METEB

Barre autolubrificanti, Bronzo BP25



BLH60

Rinvio angolare a L, da 19 a 70 Nm




CHB

Braccio di reazione, Braccio di reazione per riduttori CHB



PAV

Piede fisso, Antivibrante

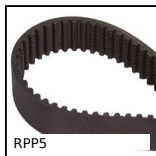

RPP5

Cinghia di trasmissione RPP, RPP5



PAS

Maniglia a ponte, Reinforced PA thermoplastic



SSB

Ingranaggio conico inox, 1:1




BOXsap

Box kit di spine elastiche ISO8752, Box kit - elastica cilindrica IS...



G1

Ingranaggio dritto acciaio, Acciaio 20NCD2

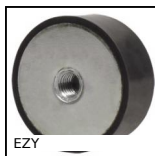

EZY

Piedino antivibrante cilindrico, Acciaio



AT5M AT10M

Cinghia aperta al metro tipo AT, AT5 Poliuretano armatura in acciaio

Prodotti correlati



MRA

Maglia rapida, Acciaio



MRA_SS

Maglia rapida, Inox



MRASeco

Maglia rapida economica, Inox



CHN_CHNSS

Catena dritta a maglie lunghe, Acciaio zincato