

Cylindrical Master-Plate® glueable insert Ø38

MSP38

Inox 316L


- Glueable stainless steel plate with tapped insert or threaded stud
- Material:
316L stainless steel

Applications



- Industrial, transport, building, furnishings

Info.

- Glue not supplied
- Not supplied individually, contact us for details

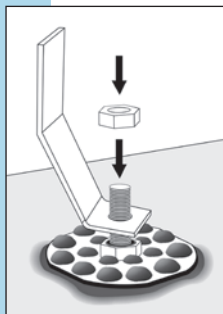

Exemple d'application

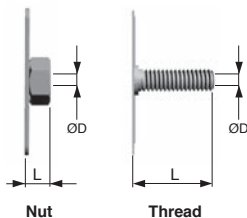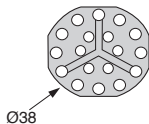

DISCOUNTS

Qty	1+	50+	100+	500+
Disc.	List	-10%	-20%	On request


Part number	ØA	ØD	L	Form	Price each 1 to 49
MSP38EB-8-6/SS	38	M8	6,5	Blind tapped	3,11 €
MSP38E-8-6/SS	38	M8	6,5	Nut	3,11 €
MSP38F-6-40/SS	38	M6	40	Thread	3,11 €
MSP38F-8-40/SS	38	M8	40	Thread	3,51 €

Dimensions in mm

Altri prodotti...



SFE
Testa a snodo
femmina, Inox / PTFE

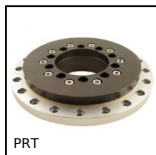

PRT
Corona girevole
Iglidur®, Iglidur®,
alluminio e inox



BOX-CSss
Fascette di serraggio,
Valigetta di fascette
inox



NPTF30
Morsetto di
collegamento,
Distanziale Ø14 a Ø20



UCP
Cuscinetto ritto in
ghisa, Ghisa



VLBG
Anello di
sollevamento,
Girevole



SSDB
Ingranaggio conico
inox, 2:1



APB_BOU
Asse per morsetti,
Tappo di sicurezza



GCL
Guida lineare a sfere
Eco, economica



LC
Limitatore di coppia
ad attrito, 30 a 240



SVT15
Martinetto a vite - Vite
traslante, Vite



DOMI80
Kit di raccordo, Kit di
raccordo XY

Prodotti correlati



MSP3815
Inserto con piastrina a
incollare
Masterplate®,
rettangolare con in...



MSP38
Inserto con piastrina a
incollare
Masterplate®,
Cilindrico Ø38 con...



MSP23
Inserto con piastrina a
incollare
Masterplate®,
Cilindrico Ø23 con...



MSP3815
Inserto con piastrina a
incollare
Masterplate®,
rettangolare con dado