
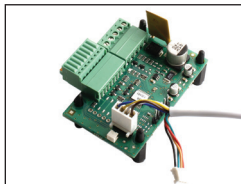
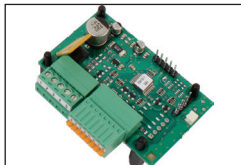


- **Digital motor servo amplifier for driving motors (>90W)**
- Accepts limit switch inputs
- Small size
- Easily configured using a PC, RS232 cable required (not supplied)

Accessories

- **MDPOT-10T/10K** Control potentiometer
- Power supplies

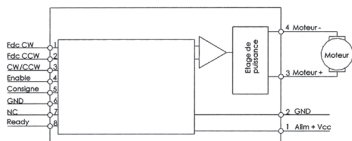

| Technical specifications | | 30V/3A | |
|--------------------------------|-----------------------------------|-----------------------------------|--|
| - Max Power | 90W | - Under voltage | Yes |
| - Power Supply | 10 to 30 Vdc | - Over-current | Adjustable |
| - Max permanent output current | 3A | - Motor short circuit | Yes |
| - Operating mode | PWM, 1 quadrant | - Short circuit on inputs | Yes |
| Inputs | | Environment | |
| - Speed control | External voltage 0/10V | - Working temperature | 0 to 40°C |
| - Enable | Voltage free contact (earthed) | - Storage temperature | -40 to +85°C |
| - Direction | Voltage free contact (earthed) | - Relative humidity | 20 to 80 %non-condensing |
| - Limit switches | 2 Voltage free contacts (earthed) | Connections | |
| Outputs | | - Connectors | Spring loaded terminals, pitch 2.54mm. Wire size : 0.14 to 1.5mm ² |
| - Ready | Open collector, 30Vdc 20mA | - Connectors (motor + supply) | Screw clamp terminals, pitch 3.81mm. Wire size : 0.14 to 1.5mm ² |
| Controls | | Mechanical characteristics | |
| - Max speed | Analogue voltage | - Dimensions | 50x100x32mm |
| - Max current | Analogue voltage | - Weight | 105g |
| Protection | | - Mounting: | Uses M4 screws |
| - Reverse polarity | Resettable fuse | | |
| - Over voltage | Yes | | |

DISCOUNTS

| | | | |
|-------|-------|-----|------------|
| Qty. | 1+ | 6+ | 10+ |
| Disc. | List. | -7% | on request |

| Part number | Mounting | Screw spacing cable | Weight (g) | Price each 1 to 5 |
|----------------|----------|-----------------------|------------|-------------------|
| NANODC-1Q-30/3 | M4 screw | 34x54 | 0,11 | 125,25 € |
| NANODC-RS232 | | Cable NANO DC - RS232 | | 94,29 € |

Dimensions in mm

Altri prodotti...




ACL-PL

Elementi di giunzione,
Piastra di fissaggio -
86x86 mm



VRSF

Anello di
sollevamento,
Orientabile maschio

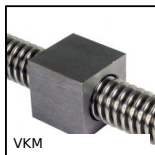


VKM

Dado quadrato in
acciaio, Acciaio - 1
filletto



CHB

Riduttore a ruota e
vite senza fine, fino a
41 Nm

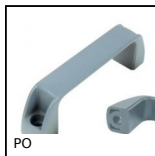

PO

Maniglia a ponte -
Multi-settore, Foro
liscio



PRF_FIX_STD

Fissaggio, Fissaggio
standard



CLQ

Cuscinetti a sfere -
Accessorio, Spessori
metallici centesimali a
na...



SEV

Attrezzo di bloccaggio
a tirante, A tirante
verticale - acciaio



PP60

Riduttore a ruota e
vite senza fine, da
17.80 a 34 Nm



STC

Deceleratore, Ghiera
d'arresto



PCS62K

Pignone a catena
dentatura temprata,
15.875mm (DIN10B-1)



LWL

Guida lineare a sfere -
Sfere inox, Carello -
da 514 N a 16700 N

Prodotti correlati



DOG319

Motoriduttore DC 12V
e 24V DC, da 4 a 9
Nm



DOG111

Motoriduttore DC 12V
e 24V DC, da 1.5 a 6
Nm