
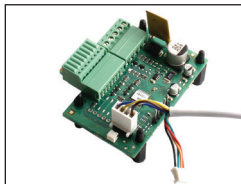
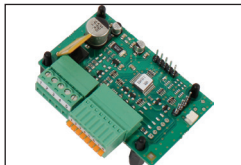


- **Digital motor servo amplifier for driving motors (>90W)**
- Accepts limit switch inputs
- Small size
- Easily configured using a PC, RS232 cable required (not supplied)

Accessories

- **MDPOT-10T/10K** Control potentiometer
- Power supplies

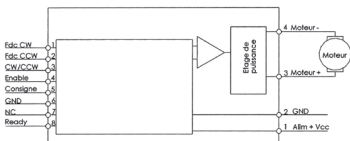

Technical specifications		30V/3A	
- Max Power	90W	- Under voltage	Yes
- Power Supply	10 to 30 Vdc	- Over-current	Adjustable
- Max permanent output current	3A	- Motor short circuit	Yes
- Operating mode	PWM, 1 quadrant	- Short circuit on inputs	Yes
Inputs		Environment	
- Speed control	External voltage 0/10V	- Working temperature	0 to 40°C
- Enable	Voltage free contact (earthed)	- Storage temperature	-40 to +85°C
- Direction	Voltage free contact (earthed)	- Relative humidity	20 to 80 %non-condensing
- Limit switches	2 Voltage free contacts (earthed)	Connections	
Outputs		- Connectors	Spring loaded terminals, pitch 2.54mm. Wire size : 0.14 to 1.5mm ²
- Ready	Open collector, 30Vdc 20mA	- Connectors (motor + supply)	Screw clamp terminals, pitch 3.81mm. Wire size : 0.14 to 1.5mm ²
Controls		Mechanical characteristics	
- Max speed	Analogue voltage	- Dimensions	50x100x32mm
- Max current	Analogue voltage	- Weight	105g
Protection		- Mounting:	Uses M4 screws
- Reverse polarity	Resettable fuse		
- Over voltage	Yes		

DISCOUNTS

Qty.	1+	6+	10+
Disc.	List.	-7%	on request

Part number	Mounting	Screw spacing cable	Weight (g)	Price each 1 to 5
NANODC-1Q-30/3	M4 screw	34x54	0,11	125,25 €
NANODC-RS232		Cable NANO DC - RS232		94,29 €

Dimensions in mm

Altri prodotti...



SH4
Ingranaggio elicoidale
ad assi paralleli,
Acciaio 20NCD2



NPCR
Morsetto porta
fotocellule, Regolabile



BLM
Pressore liscio a
molla, Corpo
termoplastica



ZBRA
Ingranaggio conico in
plastica, 1:1



PO
Maniglia a ponte -
Multi-settore, Foro
liscio



KKP-AR
Manicotto a sfere
inclinate, Carichi
elevati / -20° +200°



BS2
Panamech, Multi-
Beam, Alluminio - con
vite a pressione




BPPL
Attrezzo di montaggio
per sfera portante,
Attrezzi di montaggio



LVT
Mini martinetto
motorizzato 4A, 4



DFG
Ventosa, silicone

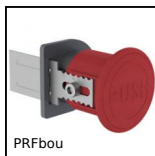

PRFbou
Sistema di chiusura,
Pulsante apriporta di



HS
Distanziatore
esagonale, Inox 303

Prodotti correlati



DOG319
Motoriduttore DC 12V
e 24V DC, da 4 a 9
Nm



DOG111
Motoriduttore DC 12V
e 24V DC, da 1.5 a 6
Nm