
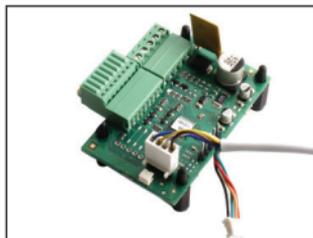


- **Digital motor servo amplifier for driving motors (>90W)**
- Accepts limit switch inputs
- Small size
- Easily configured using a PC, RS232 cable required (not supplied)

Accessories

- **MDPOT-10T/10K** Control potentiometer
- Power supplies

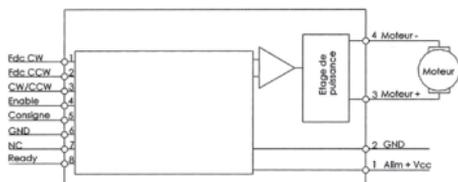

Technical specifications		30V/3A	
- Max Power	90W	- Under voltage	Yes
- Power Supply	10 to 30 Vdc	- Over-current	Adjustable
- Max permanent output current	3A	- Motor short circuit	Yes
- Operating mode	PWM, 1 quadrant	- Short circuit on inputs	Yes
Inputs		Environment	
- Speed control	External voltage 0/10V	- Working temperature	0 to 40°C
- Enable	Voltage free contact (earthed)	- Storage temperature	-40 to +85°C
- Direction	Voltage free contact (earthed)	- Relative humidity	20 to 80 %non-condensing
- Limit switches	2 Voltage free contacts (earthed)	Connections	
Outputs		- Connectors	Spring loaded terminals, pitch 2.54mm. Wire size : 0.14 to 1.5mm ²
- Ready	Open collector, 30Vdc 20mA	- Connectors (motor + supply)	Screw clamp terminals, pitch 3.81mm. Wire size : 0.14 to 1.5mm ²
Controls		Mechanical characteristics	
- Max speed	Analogue voltage	- Dimensions	50x100x32mm
- Max current	Analogue voltage	- Weight	105g
Protection		- Mounting:	Uses M4 screws
- Reverse polarity	Resettable fuse		
- Over voltage	Yes		

DISCOUNTS

Qty.	1+	6+	10+
Disc.	List.	-7%	on request

Part number	Mounting	Screw spacing cable	Weight (g)	Price each 1 to 5
NANODC-1Q-30/3	M4 screw	34x54	0,11	125,25 €
NANODC-RS232		Cable NANO DC - RS232		94,29 €

Dimensions in mm

Altri prodotti...



ESCON

Accessori per variatore di velocità 5A, Kit 4 cavi motore DC



TK

Manicotto a sfere autoallineante Topball, Autoallineante,



T10_21_AL

Puleggia dentata di posizionamento tipo T, Serie economica - T10 all...



CLG2

Ingranaggio dritto in plastica stampata , Nylon stampato



PSPE22

Conical flexible shaft handlee Ø22, Black PVC



G0

Ingranaggio dritto acciaio, Acciaio 20NCD2



PSPT

Manopola a pressione, PVC



NCT

Giunto di collegamento, Ad angolo fisso




HTD14M_85

Puleggia dentata di trasmissione tipo



BLHT40

Rinvio angolare a T, da 4 a 10.30 Nm

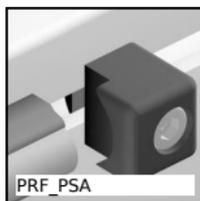

PRF_PSA

Rotella per profilo alluminio, per



ES

Bipod support base, Plastic

Prodotti correlati



DOG319

Motoriduttore DC 12V e 24V DC, da 4 a 9 Nm



DOG111

Motoriduttore DC 12V e 24V DC, da 1.5 a 6 Nm