

Cam follower without axial guide


NAST IKO

With interior ring


- For shaft diameters from 6mm to 50mm
- With external cylindrical cage
- With wiper seals
- Material: steel
- Working temperature: -20°C to +120°C

Assembly

- Use with rails with a minimum hardness of 40 HRC
- Tolerance of shaft: g6, h6

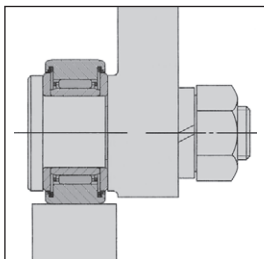

Typical application

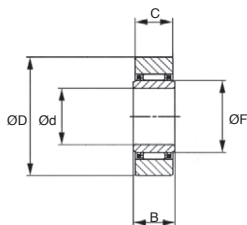

DISCOUNTS

Qty.	1+	6+	20+	40+
Disc.	List	-15%	-20%	On request

Part number	Ød	ØD	B	C	ØF	Static load Co (N)	Dynamic load C (N)	Max. load on rail (N)	Weight (g)	Stock*	Price each 1 to 5
NAST-6	6	19	10	9,8	10	4550	4160	3550	17,8	✓	12,99 €
NAST-8	8	24	10	9,8	12	5890	5650	3980	28,0	✓	14,31 €
NAST-10	10	30	12	11,8	14	9680	9790	5610	49,5	✓	22,83 €
NAST-12	12	32	12	11,8	16	10900	10500	5990	58,0	✓	23,56 €
NAST-15	15	35	12	11,8	20	14300	12400	6550	62,0	-	24,35 €
NAST-17	17	40	16	15,8	22	20900	17600	10900	109,0	✓	25,97 €
NAST-20	20	47	16	15,8	25	24500	19400	12800	157,0	✓	29,10 €
NAST-25	25	52	16	15,8	30	28400	20800	14100	180,0	✓	31,19 €
NAST-30	30	62	20	19,8	38	45400	30500	22100	320,0	-	35,97 €
NAST-35	35	72	20	19,8	42	50600	32400	25700	440,0	-	37,00 €
NAST-40	40	80	20	19,8	50	61100	35900	26900	530,0	✓	46,15 €
NAST-45	45	85	20	19,8	55	66400	37400	28500	580,0	-	49,54 €
NAST-50	50	90	20	19,8	60	71700	38900	30200	635,0	-	56,35 €

*Depending on availability - Dimensions in mm

Altri prodotti...



DOG111

Motoriduttore DC 12V e 24V DC, da 1.5 a 6 Nm



FDS

Flexible drive shaft, Masterflex® Steel, with PVC casing



BSM

Pressore a molla con esagono incassato, corpo e spina inox 303




PITAss

Pistoncino a molla, con maniglia a T



TBD

Tavola di posizionamento a passo inverso manuale, 40kg

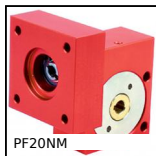

PF20NM

Riduttore a ruota e vite senza fine, fino a 5 Nm



SSB

Ingranaggio conico inox, 1:1




NT92

Riduttore coassiale a treni paralleli, da 15 a 40 Nm - a treni paral...



HTD8M_50

Puleggia dentata di trasmissione tipo HTD, HTD8 Ghisa

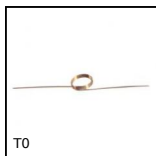

T0

Molla di torsione, Inox



H0

Ingranaggio elicoidale ad assi incrociati a 90°, Acciaio 20NCD2



PRES

Accessori per pressa PRES-3HR e PRES-4HR, Coppia di dadi per scanala...

Prodotti correlati



RNAST

Rotelle, Senza anello interno



CF

Perno folle, Standard - acciaio