

# Cam follower without axial guide


## NAST IKO

## With interior ring


- For shaft diameters from 6mm to 50mm
- With external cylindrical cage
- With wiper seals
- Material: steel
- Working temperature: -20°C to +120°C

### Assembly

- Use with rails with a minimum hardness of 40 HRC
- Tolerance of shaft: g6, h6

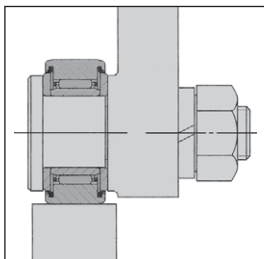

Typical application

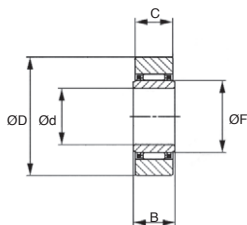

### DISCOUNTS

Qty.	1+	6+	20+	40+
Disc.	List	-15%	-20%	On request

Part number	Ød	ØD	B	C	ØF	Static load Co (N)	Dynamic load C (N)	Max. load on rail (N)	Weight (g)	Stock*	Price each 1 to 5
NAST-6	6	19	10	9,8	10	4550	4160	3550	17,8	✓	12,99 €
NAST-8	8	24	10	9,8	12	5890	5650	3980	28,0	✓	14,31 €
NAST-10	10	30	12	11,8	14	9680	9790	5610	49,5	✓	22,83 €
NAST-12	12	32	12	11,8	16	10900	10500	5990	58,0	✓	23,56 €
NAST-15	15	35	12	11,8	20	14300	12400	6550	62,0	-	24,35 €
NAST-17	17	40	16	15,8	22	20900	17600	10900	109,0	✓	25,97 €
NAST-20	20	47	16	15,8	25	24500	19400	12800	157,0	✓	29,10 €
NAST-25	25	52	16	15,8	30	28400	20800	14100	180,0	✓	31,19 €
NAST-30	30	62	20	19,8	38	45400	30500	22100	320,0	-	35,97 €
NAST-35	35	72	20	19,8	42	50600	32400	25700	440,0	-	37,00 €
NAST-40	40	80	20	19,8	50	61100	35900	26900	530,0	✓	46,15 €
NAST-45	45	85	20	19,8	55	66400	37400	28500	580,0	-	49,54 €
NAST-50	50	90	20	19,8	60	71700	38900	30200	635,0	-	56,35 €

\*Depending on availability - Dimensions in mm

## Altri prodotti...




DOMI50

Accessori di collegamento, Leva di serraggio



CPAS-H

Squadra pieghevole, Per carico pesante

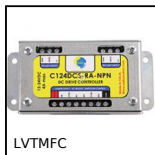

LVTMFC

Device for controlling limit switches, For mini-actuator LVT



RPP

Piastra di giunzione per cinghia RPP, RPP5



PLC\_PLT

Magnete, Con foro centrale



PR880

Ruota di rinvio, Serie 880



RHTplss

Ruota alte temperature, fino a 200kg



DOMI120

Accessori di collegamento, Leva di serraggio



PTA50

Piede snodato con base stampata Ø50, Ø




Q1

Cuscinetto orientabile a sfere, Acciaio



FF20

Riduttore ad alberi paralleli, da 5.80 a 23

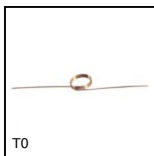

T0

Molla di torsione, Inox

## Prodotti correlati



RNAS1

Rotelle, Senza anello interno



CF

Perno folle, Standard - acciaio