


- Offers multiple connection possibilities for vacuum gripping system elements
- Material :
Aluminium
- Fixing kit not supplied

Advantages


- Compatible with 20-30mm profiles and 40-60mm profiles with rectangular mounting holes

Accessories



- PRF-ECLM8 nut
- M8 screw, length 20-22mm

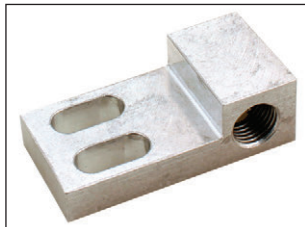

NEW!

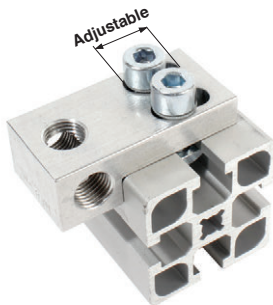

Typical mounting arrangement

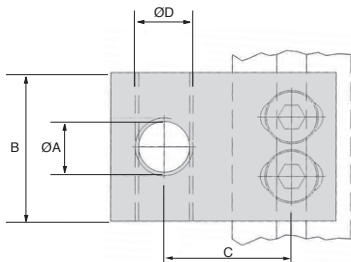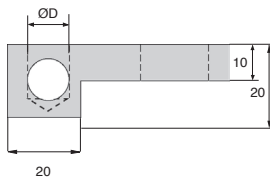

DISCOUNTS

Qty	1+	10+	30+
Disc.	List -5%	On request	

Part number	ØA	B	C	ØD	Weight (g)	Price each 1 to 9
NDS-1/4/C	G1/4"	30	29-39	G1/4"	94	30,28 €

Dimensions in mm

Altri prodotti...



BLHB30

Rinvio angolare ad albero cavo, fino a 4.47 Nm



DB

Ingranaggio conico in acciaio, 2:1



UGH25

Unità di guida tipo H, Per martinetti Ø25



ACLEFS

Elementi di ancoraggio, Standard



VLBS

Anello di sollevamento, Articolato - a saldare



BAN

Connettore / supporto per profili alluminio, Regolabile



GP75

Chiusura a leva molla a trazione compensata, Standard (GP75)



SLB

Pistoncino a molla, inox



DOG319

Motoriduttore DC 12V e 24V DC, da 4 a 9 Nm



MDR

Grillo con chiodo ad occhio, Acciaio



AT10courroie

Cinghia di posizionamento AT, AT10 Poliuretano



RJA00_02

Guarnizione in gomma, Da agganciare

Prodotti correlati



PRF_ECL

Fissaggio, Dado quadrato con linguetta - Acciaio