


- Offers multiple connection possibilities for vacuum gripping system elements
- Material :
Aluminium
- Fixing kit not supplied

Advantages

- Compatible with 20-30mm profiles and 40-60mm profiles with rectangular mounting holes

Accessories



- PRF-ECLM8 nut
- M8 screw, length 20-22mm

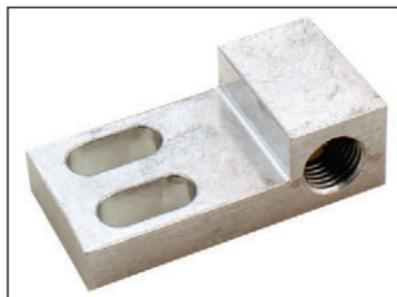

NEW!



Typical mounting arrangement

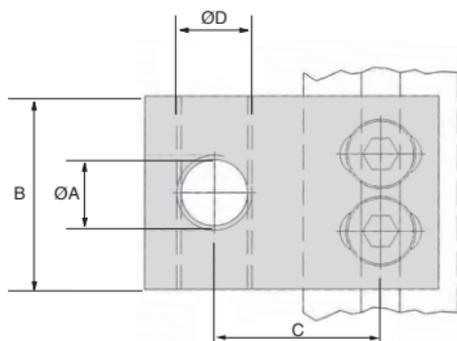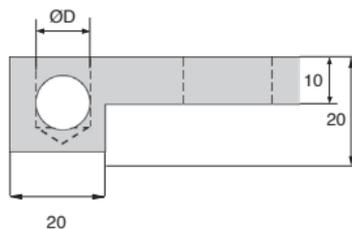

DISCOUNTS

Qty	1+	10+	30+
Disc.	List -5%	On request	

Part number	ØA	B	C	ØD	Weight (g)	Price each 1 to 9
NDS-1/4/C	G1/4"	30	29-39	G1/4"	94	30,28 €

Dimensions in mm

Altri prodotti...



SBF

Open flange bearing unit for food industry, cover



T5P_T10P

Piastra di giunzione per cinghia T, T10



TUBE25_25

Tubo quadrato, Alluminio




CAP821

Catena a tapparella dritta, Larga serie 821



FTSN

Albero supportato per guida lineare, Albero acciaio / supporto allu...

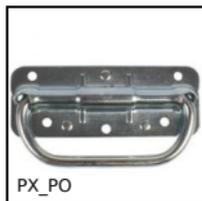

PX_PO

Maniglia - movimentazione manuale, con piastra posteriore



LRR22

Small dimension latch with locking system, Aluminium



NPTF30

Morsetto di collegamento, Distanziale Ø14 a Ø20



AF

Giunto rigido con cava chiave, Set screw



HDSS

Giunto cardanico - inox, Sollecitazioni intense



VQTplqn

Chiusura ¼ di giro - Piastra di bloccaggio, Montaggio ad incastro



MEF

Cuscinetto cilindrico, Lega di ferro FP20 autolubrificante METAFRAM

Prodotti correlati



PRF_ECL

Fissaggio, Dado quadrato con linguetta - Acciaio