

Double cross clamp



NDS

Crossed or parallel


- For $\varnothing 20$ tubes or shafts
- Multiple connection possibilities, either at right angles or for extending length of tubular elements
- Material :
Aluminium with steel screws

Advantages


- Clip on, tool free assembly




Crossed version

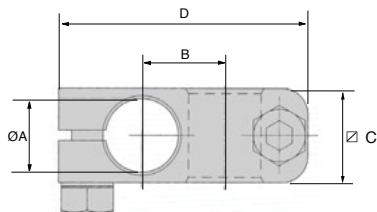

NDS-20/C

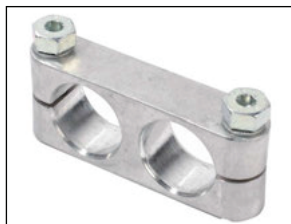

Parallel version

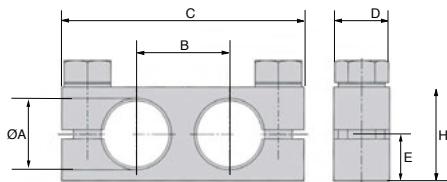

NDS-20/P

NEW!

DISCOUNTS

Qty	1+	10+	30+
Disc.	List	-5%	On request

Part number	Type	$\varnothing A$	B	C	D	H	E	Weight (g)	Price each 1 to 9
NDS-20/C	crossed	20	22	24	60	-	-	58	24,97 €
NDS-20/P	parallel	20	26	64	14	25	12,5	60	23,16 €


Dimensions in mm

Altri prodotti...



CHM50

Riduttore a ruota e vite senza fine, fino a 107 Nm

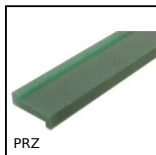

PRZ

Profilo supporto per catena, Profilo a Z da posare



PDM_PDV

, by metal detectors



PAV

Piede fisso, Antivibrante



SUPss

Calettatore di bloccaggio autocentrante inox, Senza ghiera



PRF_PL_4590

Elementi di giunzione, Piastra di giunzione - 45x90 mm




M0

Coppia ruota e vite senza fine, Bronzo



PM3

Coppia ruota e vite senza fine, Plastica lavorata (delrin)

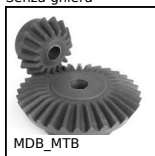

MDB_MTB

Ingranaggio conico in plastica stampata, 2:1



PRF_FIX_ANG

Fissaggio, Fissaggio angolare



EKGS

Giunto senza gioco Gerwah®, da 0.5 a 35Nm



LFM2

Vite trapezoidale acciaio, Acciaio semiduro - 2 filetti

Prodotti correlati



NDS20

Connettore di serraggio, Parallela