

# Double cross clamp



## NDS

## Crossed or parallel


- For  $\varnothing 20$  tubes or shafts
- Multiple connection possibilities, either at right angles or for extending length of tubular elements
- Material :  
Aluminium with steel screws

### Advantages


- Clip on, tool free assembly




Crossed version

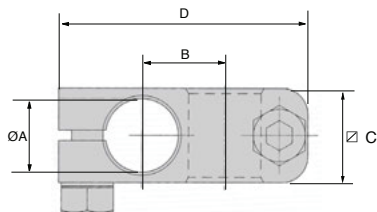

NDS-20/C

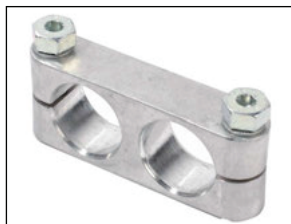

Parallel version

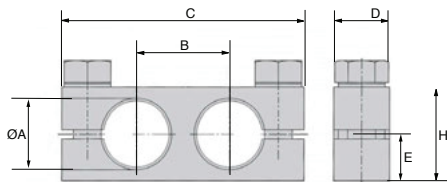

NDS-20/P

**NEW!**

### DISCOUNTS

Qty	1+	10+	30+
Disc.	List	-5%	On request

Part number	Type	$\varnothing A$	B	C	D	H	E	Weight (g)	Price each 1 to 9
NDS-20/C	crossed	20	22	24	60	-	-	58	24,97 €
NDS-20/P	parallel	20	26	64	14	25	12,5	60	23,16 €

Dimensions in mm

## Altri prodotti...



RPC  
Ruota, Poliammide



G01  
Giunto cardanico  
semplice,  
Sollecitazioni normale



PTKss  
Piede speciale  
agroalimentare, Inox -  
3-A standard



G4  
Ingranaggio dritto  
acciaio , Acciaio  
20NCD2



PLM-C  
Magnete cilindrico di  
fermo, Magnete di  
fermo cilindrico



CHAK  
Cerniera, Hi-Klik™ - di  
posizionamento



PT880  
Pignone di trazione,  
Serie 880



SH1  
Ingranaggio elicoidale  
ad assi paralleli,  
Plastica lavorata  
(delrin)



BLH30  
Rinvio angolare a L,  
da 1.32 a 4.40 Nm



GTCSS  
Rullo tendicinghia, Per  
ambienti aggressivi



GE  
Chiusura a leva,  
Standard



SEV  
Attrezzo di bloccaggio  
a tirante, A tirante  
verticale - inox

## Prodotti correlati



NDS20  
Connettore di  
serraggio, Incrociata