

Double cross clamp



NDS

Crossed or parallel


- For $\varnothing 20$ tubes or shafts
- Multiple connection possibilities, either at right angles or for extending length of tubular elements
- Material :
Aluminium with steel screws

Advantages


- Clip on, tool free assembly




Crossed version

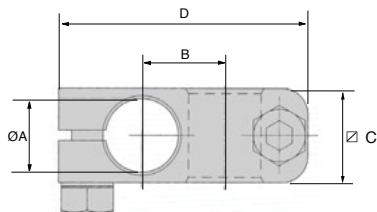

NDS-20/C

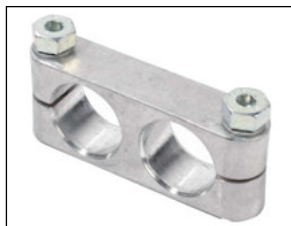

Parallel version

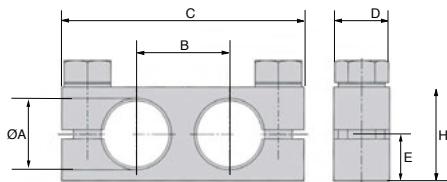

NDS-20/P

NEW!

DISCOUNTS

Qty	1+	10+	30+
Disc.	List	-5%	On request

Part number	Type	$\varnothing A$	B	C	D	H	E	Weight (g)	Price each 1 to 9
NDS-20/C	crossed	20	22	24	60	-	-	58	24,97 €
NDS-20/P	parallel	20	26	64	14	25	12,5	60	23,16 €


Dimensions in mm

Altri prodotti...



BAG

Anello di bloccaggio in acciaio, Acciaio

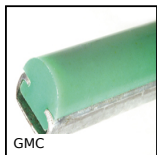

GMC

Guida prodotto laterale tonda, Per imbottigliamento e imballaggio



ACLEPP

Angolare, 4 fori



PTA40

Articulated foot with solid base foot Ø 40, 30000N



CLLCLLP

Forcella serie lunga, Lunga acciaio



PITAss

Pistoncino a molla, con maniglia a T



H4

Ingranaggio elicoidale ad assi incrociati a 90°, Acciaio 20NCD2



CHM63

Riduttore a ruota e vite senza fine, fino a 196 Nm



BFA

Anelli d'arresto per alberi, Anello tipo E



PF30NM

Riduttore a ruota e vite senza fine, fino a 8.8 Nm



BMM

Manopola, zigrinata



CHC

Vite a testa cava esagonale CHC, Acciaio classe 12.19

Prodotti correlati



NDS20

Connettore di serraggio, Parallela