

Double cross clamp



NDS

Crossed or parallel


- For $\varnothing 20$ tubes or shafts
- Multiple connection possibilities, either at right angles or for extending length of tubular elements
- Material :
Aluminium with steel screws

Advantages

- Clip on, tool free assembly




Crossed version

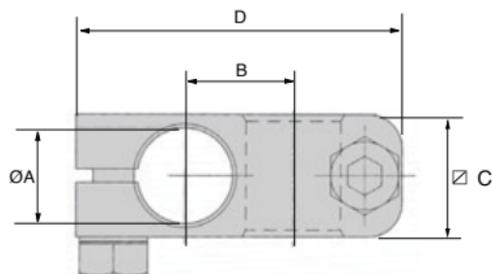

NDS-20/C



Parallel version

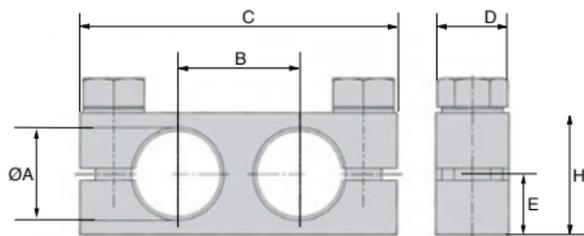

NDS-20/P

NEW!

DISCOUNTS

Qty	1+	10+	30+
Disc.	List	-5%	On request

Part number	Type	$\varnothing A$	B	C	D	H	E	Weight (g)	Price each 1 to 9
NDS-20/C	crossed	20	22	24	60	-	-	58	24,97 €
NDS-20/P	parallel	20	26	64	14	25	12,5	60	23,16 €

Dimensions in mm

Altri prodotti...




BLH40

Rinvio angolare a L,
da 3 a 10.30 Nm



BTCW

Tappo inox per tubo
quadrato, A saldare

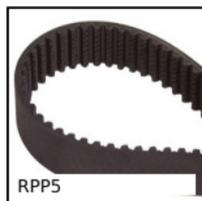

RPP5

Cinghia di
trasmissione RPP,
RPP5



ZDB

Ingranaggio conico in
plastica, 2:1



GLT3E-58

Guide telescopiche
acciaio, Estensione
extra



H0

Ingranaggio elicoidale
ad assi incrociati a
90°, Acciaio 20NCD2



MEB

Ingranaggio conico in
plastica stampata, 1:1



SSDB

Ingranaggio conico
inox, 2:1



HSSs

Vite a spalla di
precisione inox
ISO7379, Inox ISO
7379



PSG125

Ingranaggio dritto di
precisione, Acciaio
20NCD2 cementato
temprato



PM3

Ruota per vite senza
fine, Bronzo



ESCON

Accessori per
variatore di velocità
5A, Kit 4 cavi motore
DC

Prodotti correlati



NDS20

Connettore di
serraggio, Parallela