

Double cross clamp



NDS

Crossed or parallel


- For $\varnothing 20$ tubes or shafts
- Multiple connection possibilities, either at right angles or for extending length of tubular elements
- Material :
Aluminium with steel screws

Advantages


- Clip on, tool free assembly




Crossed version

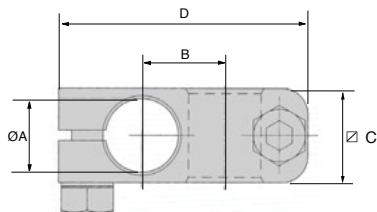

NDS-20/C

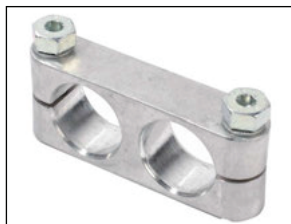

Parallel version

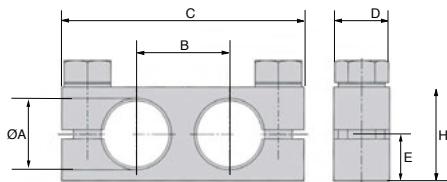

NDS-20/P

NEW!

DISCOUNTS

Qty	1+	10+	30+
Disc.	List	-5%	On request

Part number	Type	$\varnothing A$	B	C	D	H	E	Weight (g)	Price each 1 to 9
NDS-20/C	crossed	20	22	24	60	-	-	58	24,97 €
NDS-20/P	parallel	20	26	64	14	25	12,5	60	23,16 €

Dimensions in mm

Altri prodotti...



ERF

Terminale rapido per cavi, Terminale filettato



DER90

Motore inox AC asincrono da 1,1 a 1,5kW, 1,1 a 1.5kW



PAMF100EB

Piede snodato con base stampata fissabile Ø100, Piede snodato



SNG

Cuscinetto ritto polimero inox, Ghisa - In 2 metà



GPLso

Scovolo, seta



RFV63

Riduttore inox a ruota e vite senza fine, fino a 152 Nm



DOMI50

Accessori di collegamento, Piatto girevole



H0

Ingranaggio elicoidale ad assi incrociati a 90°, Acciaio 20NCD2



HLUss

Volantino a razze, Inox 316



KH

Manicotto a sfere, Leggera



BOXKU

Box kit di chiavette a disco, Box kit di



TIFss

Tirante tutto filetto - DIN976A, Inox

Prodotti correlati



NDS20

Connettore di serraggio, Parallela