

Double cross clamp



NDS

Crossed or parallel


- For $\varnothing 20$ tubes or shafts
- Multiple connection possibilities, either at right angles or for extending length of tubular elements
- Material :
Aluminium with steel screws

Advantages


- Clip on, tool free assembly




Crossed version

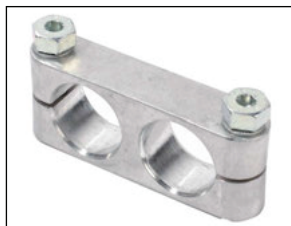

Parallel version

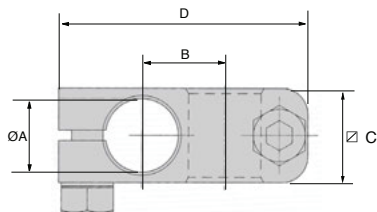

NDS-20/C

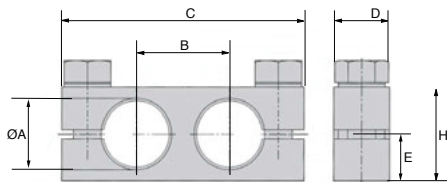

NDS-20/P

NEW!

DISCOUNTS

Qty	1+	10+	30+
Disc.	List	-5%	On request


Part number	Type	$\varnothing A$	B	C	D	H	E	Weight (g)	Price each 1 to 9
NDS-20/C	crossed	20	22	24	60	-	-	58	24,97 €
NDS-20/P	parallel	20	26	64	14	25	12,5	60	23,16 €

Dimensions in mm


Altri prodotti...



H3
Ingranaggio elicoidale ad assi incrociati a 90°, Plastica lavorata

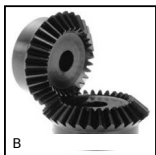

B
Ingranaggio conico - Acciaio 60C40, 1:1

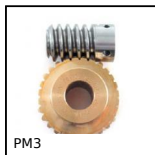

PM3
Coppia ruota e vite senza fine, Bronzo



CHV
Motovariatore meccanico, da 0,18 a 1,5kW



RTK
Giunto Bowex®, a dentatura bombata, Nylon e acciaio



G0
Ingranaggio dritto acciaio, Acciaio 20NCD2



DOMI120
Slitta di regolazione Domino 120, Slitta DOMILINE 120 con contatore ...



AC156-157
Riscontro per chiusura a leva rigida ad anello, 25.5mm



GET-AL
Giunto elastico alluminio serie eco., Alluminio



BPVM
Sfera portante avvitabile miniatura, Miniatura ad avvitare



DOMI30
Kit di raccordo, Kit di raccordo XZ



SER69K-CLE
Chiusura 1/4 di giro per agroalimentare, Chiave

Prodotti correlati



NDS20
Connettore di serraggio, Parallela