

Multiple junction clamp



NJM

For rod or tube

- For extending cylindrical sections, either in-line or parallel mounting

- Materials:

Wing knob: thermosetting plastic

Colour: dark grey

Screw: resistance class 5.8, yellow bichrome steel


Body: high-resistance anodised aluminium




Advantages

- Parallel mounting arrangement can be used to strengthen a structure

- Additional holes in body allow orthogonal joints to be assembled

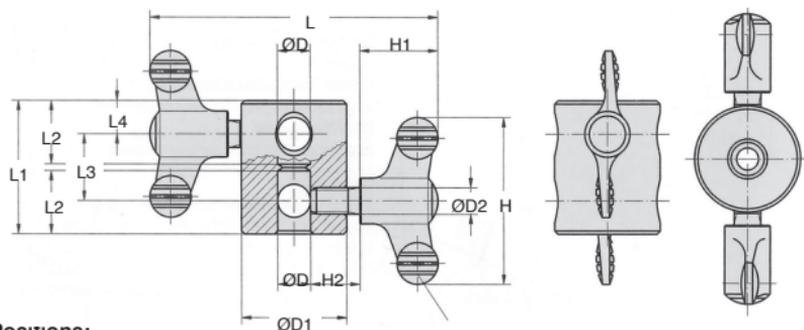

Positions:

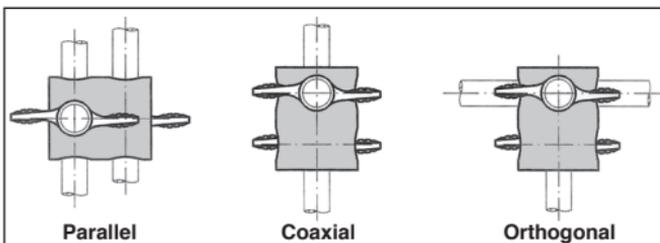

DISCOUNTS

Qty.	1+	10+	30+
Disc.		List -5%	On request

Part number	ØD	ØD1	ØD2	L	L1	L2	L3	L4	H	H1	H2	Weight (kg)	Price each	
													Stock*	1 to 9
NJM-8	8	28	M8	89	36	17	20	8	50	24	15	0,074	✓	37,80 €
NJM-10	10	32	M8	90	40	19	20	10	50	24	15	0,093	✓	39,57 €
NJM-12	12	36	M8	90	44	21	20	12	50	24	15	0,118	✓	45,25 €
NJM-16	16	45	M10	126	56	27	24	16	75	35	20	0,262	-	57,68 €

*Depending on availability - Dimensions in mm

Altri prodotti...




DOMI120

Slitta di regolazione Domino 120, Slitta DOMILINE 120 con contatore ...




BPTR

Tappo per tubo tondo, Standard

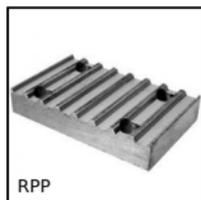

RPP

Piastra di giunzione per cinghia RPP, RPP8

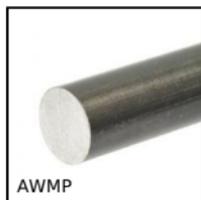

AWMP

Albero in alluminio per guida lineare, Alluminio



NTM

Grano punta in nylon, punta in nylon



PSG1

Ingranaggio dritto di precisione, Acciaio 35NCD6 pretrattato



PR882

Ruota di rinvio, Serie 882



SVT20

Martinetto a vite - Vite traslante, Vite traslante



TOL

Testa orientabile, Lunga



HTD5M_25

Puleggia dentata di trasmissione tipo HTD, HTD5 Alluminio



BC2

Panamech, Multi-Beam, Alluminio - con ganascia di serraggio



UTKpwr

Guida lineare Utilitrack®, Profilo guida a V

Prodotti correlati



NSA

Connettore rinvio d'angolo, Articolato



NSR

Connettore rinvio d'angolo, Regolabile