

Articulated clamp




NSA

For rod or tube

- Holds cylindrical sections (rods, tubes...)
- With wing nut
- Materials:
Wing knob: thermosetting plastic
Colour: dark grey
Clamp: high-resistance anodised aluminium
Bar and socket: shiny polished chrome-finished steel

Advantages

- Adjustable without bearing
- Wing nut style knob means quickly tightened

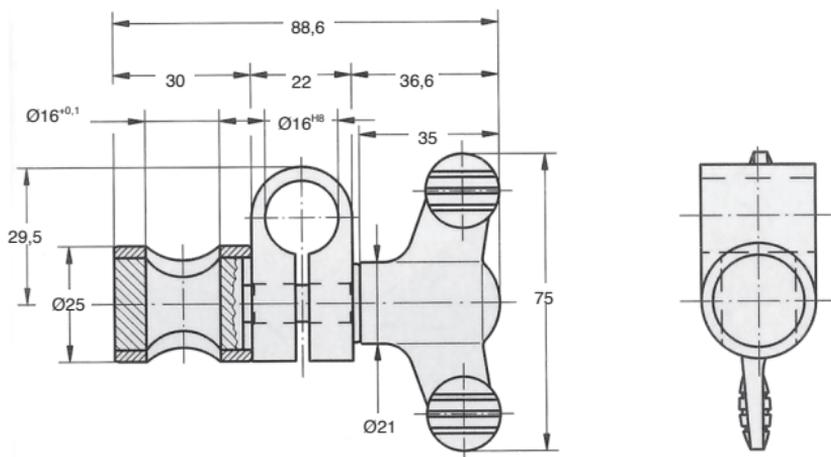

DISCOUNTS

Qty.	1+	10+	30+
Disc.	List -5%	On request	

Part number	For shaft	Weight (kg)	Stock*	Price each 1 to 9
NSA-16	Ø16	0,150	✓	52,16 €

*Depending on availability - Dimensions in mm

Altri prodotti...




BSM_LOK

Pressore a molla con esagono incassato, LONG-LOK - corpo e spina in ...



T5M_T10M

Cinghia aperta al metro tipo T, T5 Poliuretano armatura in acciaio

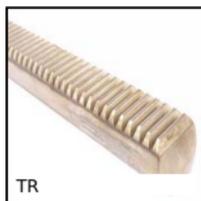

TR

Crema di sezione circolare, Inox - modulo 0,25-1,5



PW_PWG05

Vite senza fine di precisione, Acciaio



GBMf

Dado per vite a sfere, Dado flangiato a circuiti multipli



H1

Ingranaggio elicoidale ad assi incrociati a 90°, Plastica lavorata ...



CLR

Staffa di montaggio per molla a gas, Staffa di montaggio per forcell...




EKN

Giunto a soffitto Gerwah®, da 0.5 a 12Nm



YG2

Ingranaggio dritto PRESTAZIONE, Acciaio 35NCD6

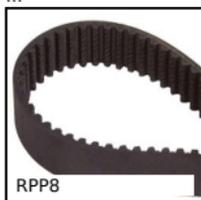

RPP8

Cinghia di trasmissione RPP, RPP8



WW20

Carrello Drylin® W, Carrello



PAMF120

Articulated fixable foot, pressed bolt-down base Ø 120, Ø 120

Prodotti correlati



NSR

Connettore rinvio d'angolo, Regolabile



NJM

Connettore rinvio d'angolo, Multiplo



NPTR

Morsetto, Regolabile



NPTR10

Connettore rinvio d'angolo, Regolabile