

Articulated clamp




NSA

For rod or tube

- Holds cylindrical sections (rods, tubes...)
- With wing nut
- Materials:
Wing knob: thermosetting plastic
Colour: dark grey
Clamp: high-resistance anodised aluminium
Bar and socket: shiny polished chrome-finished steel

Advantages

- Adjustable without bearing
- Wing nut style knob means quickly tightened

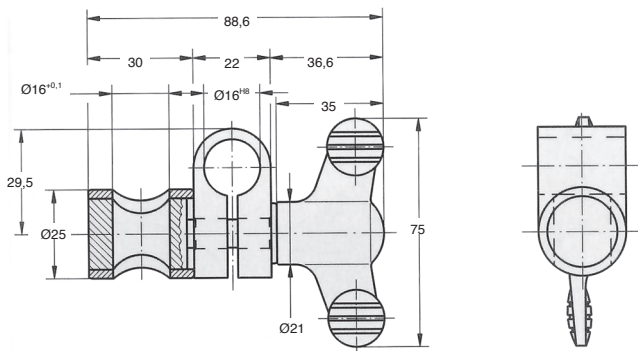

DISCOUNTS

Qty.	1+	10+	30+
Disc.	List -5%	On request	

Part number	For shaft	Weight (kg)	Stock*	Price each 1 to 9
NSA-16	Ø16	0,150	✓	52,16 €

*Depending on availability - Dimensions in mm

Altri prodotti...



CLQ

Cuscinetti a sfere -
Accessorio, Spessori
metallici centesimali a
na...



BPHR

Sfera portante, Forte



GGP

Vite ad alette,
Tecnopolimero con
inserto in acciaio



DBL880

Rotella per catena,
Serie 880 e 881



F7-SN

Visualizzatore
multifunzione,
Supporto snodato



T5-BAR

Barra dentata, T5



PRF_SDD

Supporto per sensore
Ø12, Ø12



BAB

Perno autobloccante a
sfere, Inox temprato




NK27

Guida mini Drylin® N,
Larghezza 27 mm



SVR20

Martinetto a vite - Vite
rotante, Con

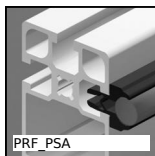

PRF_PSA

Rotella per profilo
alluminio, Supporto



GMC_GMK_BR

Morsetto porta guide,
Piatto o tondo

Prodotti correlati



NSR

Connettore rinvio
d'angolo, Regolabile



NJM

Connettore rinvio
d'angolo, Multiplo