

Articulated clamp




NSA

For rod or tube

- Holds cylindrical sections (rods, tubes...)
- With wing nut
- Materials:
Wing knob: thermosetting plastic
Colour: dark grey
Clamp: high-resistance anodised aluminium
Bar and socket: shiny polished chrome-finished steel

Advantages

- Adjustable without bearing
- Wing nut style knob means quickly tightened

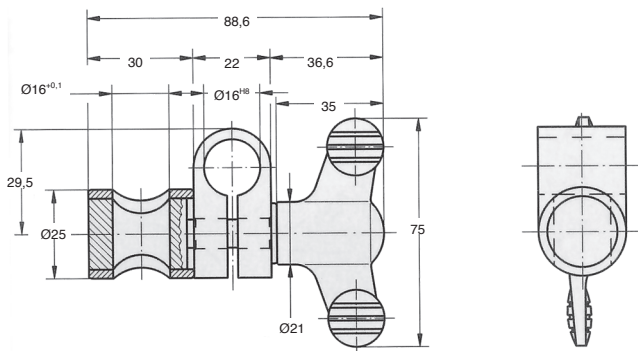

DISCOUNTS

Qty.	1+	10+	30+
Disc.	List -5%	On request	

Part number	For shaft	Weight (kg)	Stock*	Price each 1 to 9
NSA-16	Ø16	0,150	✓	52,16 €

*Depending on availability - Dimensions in mm

Altri prodotti...



PRF_ART
Cerniere e giunti,
Standard



T5-10ECO
Puleggia dentata di
posizionamento tipo
T, Serie economica -
T5 allu...



BPPL
Attrezzo di montaggio
per sfera portante,
Attrezzi di montaggio



PRS80
Piede snodato tutto
inox Ø80, Ø 80



ACLRP
Rullo per profilati, Con
cuscinetto a sfere



PRF_JL4
Panel accessories,
Guarnizione - Ø 4mm



BCM_MPBT
Spazzola cilindrica
modulare, Filo
poliestere PBT



AFA
Perno di fissaggio, con
anello



MO
Vite senza fine ,
Acciaio temprato



RBGpl
Ruota girevole a
doppio bloccaggio,
Acciaio - gomma



ADL
Anello di
sollevamento,
Femmina



PRES
Accessori per pressa
PRES-3HR e
PRES-4HR, Portapinzine

Prodotti correlati



NSR
Connettore rinvio
d'angolo, Regolabile



NJM
Connettore rinvio
d'angolo, Multiplo



NPTR
Morsetto, Regolabile



NPTR10
Connettore rinvio
d'angolo, Regolabile