

- **Rail end cap**
- The end caps are compatible with Drylin® N guide rails and prevent carriages sliding off whilst offering an aesthetic finish and protection against cuts from sharp edges




Advantages

- Easy mounting
- Low cost
- Can be removed
- High retention force


Material

- Polymer


NEW!

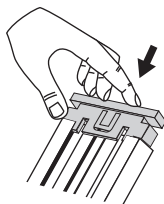

Easily assembled by hand

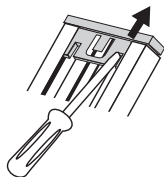

Disassembled using a screwdriver

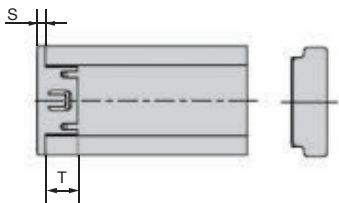

DISCOUNTS

Qty	1+	5+	10+
Disc	Prix -6%	On request	

Part number	S	T	For rail	Price each. 1 to 4
NSKB-17	1,5	7	NK02-17	7,83 €
NSKB-27	2	8	NK01-27, NK02-27	8,38 €
NSKB-40	1,5	8	NK02-40	On request
NSKB-80	2	17	NK02-80	11,50 €

Dimensions in mm

Altri prodotti...




CHT

Motore AC asincrono trifase, 0.12 a 0.22kW



5H1

Ingranaggio elicoidale ad assi paralleli, Plastica lavorata (delrin)

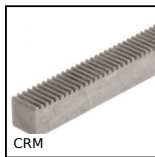

CRM

Cremagliera in nylon stampato, Nylon



T5M T10M

Cinghia aperta al metro tipo T, T10 Poliuretano armatura in acciaio



DOMI50

Accessori di collegamento, Piatto girevole



PSG3

Ingranaggio dritto di precisione, Acciaio 20NCD2 cementato temprato



GCB880

Guida curva, Serie 880 e 881




CHAsb28

Cerniera senza perno in rotoli, Cerniera in polimero



CM

Attrezzi Hygienic Usit® and Hygienic Design®,

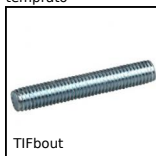

TIFbout

Tirante tutto filetto - DIN976A, Acciaio



MRS

Cremagliera sezione metrica, Inox



WFRM

Dado trapezoidale, Polimero (Iglidur®) - 1 filetto

Prodotti correlati