



Spur gear coaxial gearbox

Torque up to 14Nm


NT61
NH61

- Ratios from 1:1 to 9:1 (other ratios available on request)
- Output backlash: N/A
- Max. input speed: 3000 rpm
- Materials:
 - casing: anodised aluminium
 - input & output: unhardened steel
- Weight: 0.6 / 1.2kg
- keyway conforms to DIN 6885




Options


- Can be adapted to suit your motor
- Ask for the ratio you require
- Also see NT62, NH62 and NT63, NH63

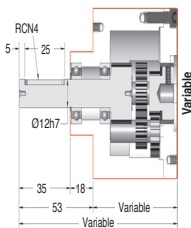

NH61

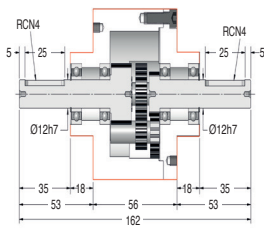

NT61

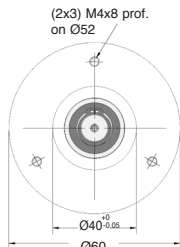

Output face

OUTPUT TORQUE (In Nm: values given as a guide only)

Ratios	2:1	3:1	4:1	5:1	6:1	8:1	9:1
3000	5,0	5,0	5,0	5,0	5,0	5,0	5,0
2000	5,5	5,5	5,5	6,0	6,0	6,0	6,0
1000	6,5	6,5	6,5	7,0	7,0	7,0	7,0
500	7,5	7,5	7,5	8,0	8,0	8,0	8,0
200	9,0	9,0	9,0	9,0	9,0	9,0	9,0
100	10,0	10,0	10,0	10,0	10,0	10,0	10,0
50	12,0	12,0	12,0	12,0	12,0	12,0	12,0
20	14,0	14,0	14,0	14,0	14,0	14,0	14,0

Large choice of reduction ratios!
Up to 120:1

DISCOUNTS

Qty.	1+	2+	4+	6+
Disc.	List	-15%	-20%	On request

Part number	Ratios	Max. input speed (rpm)	Max. output speed (rpm)	Efficiency at 1000 rpm	Module	Direction of input/output rotation	Price each
NT61-2	NH61-2	2:1	3000	1500	92%	Same	637,06 €
NT61-3	NH61-3	3:1	3000	1000	92%	Same	637,06 €
NT61-4	NH61-4	4:1	3000	750	92%	Same	637,06 €
NT61-5	NH61-5	5:1	3000	600	92%	Opposite	637,06 €
NT61-6	NH61-6	6:1	3000	500	92%	Opposite	637,06 €
NT61-8	NH61-8	8:1	3000	375	92%	Opposite	637,06 €
NT61-9	NH61-9	9:1	3000	333	92%	Opposite	637,06 €
NT61-SP	NH61-SP	1:1 - 9:1	Special ratios from 1:1 to 9:1				746,45 €

On request

Dimensions in mm


Altri prodotti...



PRF_PA
Elementi di giunzione,
Piastra di
adattamento



NKXR
Cuscinetto combinato
senza anello interno,
Needle and cylindrical
roller bearing

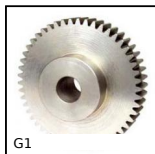

G1
Ingranaggio dritto
acciaio, Acciaio
20NCD2



SLBW
Pistoncino a molla, Da
saldare - Acciaio



CHARcav
Cerniera a molla, to
install




DOMI_MD
Tavola rotante di
regolazione Domino,
55/1



CHA35
Cerniera ad avvitare,
Cerniera



BAC105
Contenitore a becco,
8mm

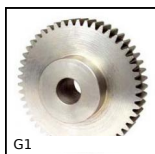

G1
Ingranaggio dritto
acciaio, Acciaio
20NCD2



H0
Ingranaggio elicoidale
ad assi incrociati a
90°, Acciaio 20NCD2



DILC
Indexing plunger with
cam, with cam



BOX-CS
Fascette di serraggio,
Valigetta di fascette
acciaio

Prodotti correlati



J66
Riduttore coassiale a
treni paralleli, da 0.90
a 2.80 Nm - a treni
paralleli



NT62
Riduttore coassiale a
treni paralleli, da 6 a
18 Nm - a treni
paralleli