

# Spur gear coaxial gearbox




## NT62 NH62

**Torque up to 18Nm**


- Ratios from 1:1 to 27:1 (other ratios available on request)
- Output backlash: N/A
- Max. input speed: 3000 rpm
- Materials:
  - casing: anodised aluminium
  - input & output: unhardened steel
- Weight: 0.61 kg

### Options


- Can be adapted to suit your motor
- Ask for the ratio you require
- Also see **NT61, NH61** and **NT63, NH63**
- keyway conforms to DIN 6885

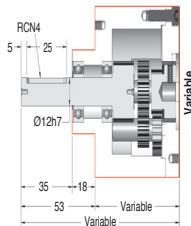

**NH62**

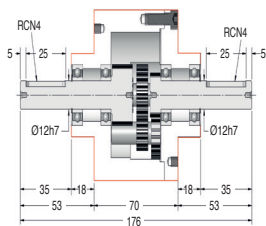

**NT62**

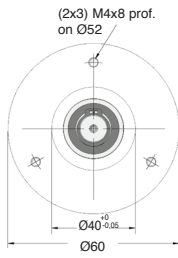

**Output face**

### OUTPUT TORQUE (In Nm, values given as a guide only)

Ratios	10:1	12:1	15:1	18:1	20:1	24:1	27:1
3000	6,0	8,0	8,0	8,0	8,0	8,0	8,0
2000	7,0	8,5	8,5	8,5	8,5	8,5	8,5
1000	8,5	9,0	9,0	9,0	9,0	9,0	9,0
500	10,0	10,0	10,0	10,0	10,0	10,0	10,0
200	11,0	12,0	12,0	12,0	12,0	12,0	12,0
100	12,0	14,0	14,0	14,0	14,0	14,0	14,0
50	14,0	16,0	16,0	16,0	16,0	16,0	16,0
20	16,0	18,0	18,0	18,0	18,0	18,0	18,0

**Large choice of reduction ratios !  
Up to 120:1**

### DISCOUNTS

Qty.	1+	2+	4+	6+
Disc.	List	-15%	-20%	On request

Part number	Ratios	Max. input speed (rpm)	Max. output speed (rpm)	Efficiency at 1000 rpm	Module	Direction of input/output rotation	Price each
NT62-10 NH62-10	10:1	3000	300	85%	Same	769,20 €	
NT62-12 NH62-12	12:1	3000	250	85%	Same	769,20 €	
NT62-15 NH62-15	15/1	3000	200	85%	Same	769,20 €	
NT62-18 NH62-18	18:1	3000	166	85%	Same	769,20 €	
NT62-20 NH62-20	20:1	3000	150	85%	Same	769,20 €	
NT62-24 NH62-24	24:1	3000	125	85%	Same	769,20 €	
NT62-27 NH62-27	27:1	3000	111	85%	Same	769,20 €	
NT62-SP NH62-SP	1:1 - 27:1	<b>Special ratios from 1:1 to 27:1</b>				877,07 €	

**On request**

Dimensions in mm

## Altri prodotti...



SVG

Chiusura a leva regolabile, Corsa da 106,7mm a 121,4mm



PCM

Impugnatura cilindrica fissa, Impugnatura non girevole



YG2

Ingranaggio dritto PRESTAZIONE, Acciaio 35NCD6



ACM\_TRI

Tirante chiusura in gomma, Caucciù



GSA\_A

Molla a gas regolabile, Acciaio



RPCplss

Ruota girevole con piastra, Inox - Poliammide



TS01\_TW01

Guida lineare su binario Drylin® T, fino al 7000 N



HBM

Guida su semi-binari, Boccola di regolazione



GAL22

Ruota per trasportatore, Acciaio



HTD14M\_55

Puleggia dentata di trasmissione tipo



V3RA\_PT

Volantino a tre razze, Poliammide



DIA

Pistoncino a molla, con anello

## Prodotti correlati



NT61

Riduttore coassiale a treni paralleli, da 5 a 14 Nm - a treni parall...



NT63

Riduttore coassiale a treni paralleli, da 8 to 20 Nm - a treni paral...