



Spur gear coaxial gearbox



Torque up to 40Nm

NT92
NH92


- Ratios from 1:1 to 36:1 (other ratios available on request)
- Output backlash: N/A
- Max. input speed: 3000 rpm
- Materials:
 - casing: anodised aluminium
 - input & output: unhardened steel
- Weight: 2 kg

Options


- Can be adapted to suit your motor
- Ask for the ratio you require
- Also see NT91, NH91
- keyway conforms to DIN 6885

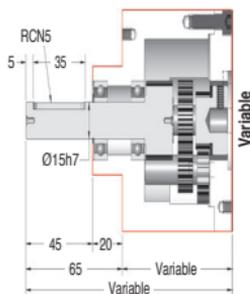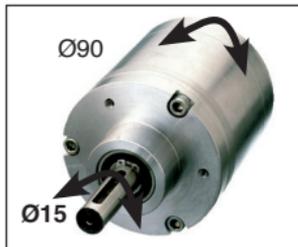

NH92

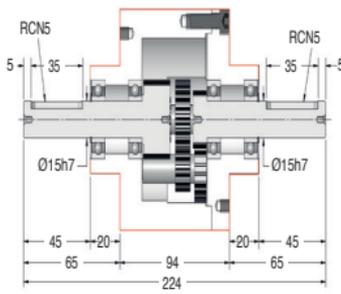

NT92

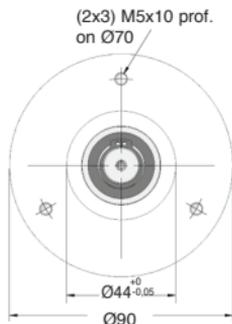

Output face

OUTPUT TORQUE (In Nm, values given as a guide only)

	Ratios	10:1	12:1	15:1	18:1	20:1	27:1	36:1
INPUT SPEED (rpm)	3000	15	15	17	17	17	18	18
	2000	18	18	20	20	20	21	21
	1000	21	21	23	23	23	24	24
	500	24	24	26	26	26	27	27
	200	27	27	29	29	29	30	30
	100	30	30	31	31	32	33	33
	50	32	33	34	34	35	36	36
	20	35	36	38	38	40	40	40

Large choice of reduction ratios!
Up to 36:1

DISCOUNTS

Qty.	1+	2+	4+	6+
Disc.	List	-15%	-20%	On request

Part number	Ratios	Max. input speed (rpm)	Max. output speed (rpm)	Efficiency at 1000 rpm	Module	Direction of input/output rotation	Price each
NT92-10 NH92-10	10:1	3000	300	84%	Same	787,90 €	On request
NT92-12 NH92-12	12:1	3000	250	84%	Same	787,90 €	
NT92-15 NH92-15	15:1	3000	200	84%	Same	787,90 €	
NT92-18 NH92-18	18:1	3000	166	84%	Same	787,90 €	
NT92-20 NH92-20	20:1	3000	150	84%	Same	787,90 €	
NT92-27 NH92-27	27:1	3000	125	84%	Same	787,90 €	
NT92-36 NH92-36	36:1	3000	83	84%	Same	787,79 €	
NT92-SP NH92-SP	1:1 - 36:1	Special ratios from 1:1 to 36:1				896,20 €	

Dimensions in mm

Altri prodotti...



PR40

Piede fissabile con snodo - poliammide, Ø 40



GLB

Volantino a 6 lobi filettato, Tecnopolimero - Inox



PGM86-M5

Maniglia a ponte, Termoplastica



BPTRW

Piastra inox a saldare tonda, A saldare




UFX

Giunto elastico UNEFLEX, range



QTR

Cuscinetto a rulli conici, Acciaio

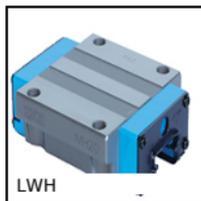

LWH

Guida lineare a sfere - Sfere acciaio, Carello - da 9320 N a 71300 N




MEB

Ingranaggio conico in plastica stampata, 1:1



RURp

Ruota girevole a doppio bloccaggio, Poliuretano - Mozzo

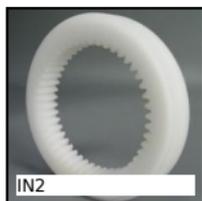

IN2

Ingranaggio interno, Plastica lavorata (delrin)



CSSSS

Snodo sferico inox, Inox/ PTFE



CHMR40

Riduttore a ruota e vite senza fine, fino a 57 Nm

Prodotti correlati



NT91

Riduttore coassiale a treni paralleli, da 10 a 35 Nm - a treni paral...



NT121

Riduttore coassiale a treni paralleli, da 20 a 68 Nm - a treni paral...