



Spur gear coaxial gearbox



Torque up to 40Nm

NT92
NH92


- Ratios from 1:1 to 36:1 (other ratios available on request)
- Output backlash: N/A
- Max. input speed: 3000 rpm
- Materials:
 - casing: anodised aluminium
 - input & output: unhardened steel
- Weight: 2 kg

Options


- Can be adapted to suit your motor
- Ask for the ratio you require
- Also see NT91, NH91
- keyway conforms to DIN 6885

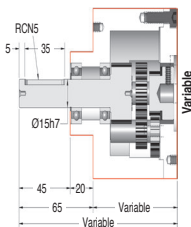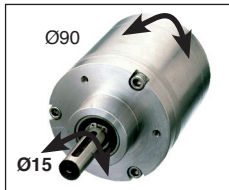

NH92

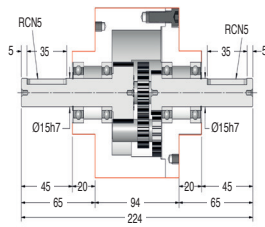

NT92

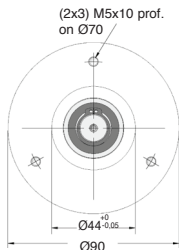

Output face

OUTPUT TORQUE (In Nm, values given as a guide only)

| | Ratios | 10:1 | 12:1 | 15:1 | 18:1 | 20:1 | 27:1 | 36:1 |
|-------------------|--------|------|------|------|------|------|------|------|
| INPUT SPEED (rpm) | 3000 | 15 | 15 | 17 | 17 | 17 | 18 | 18 |
| | 2000 | 18 | 18 | 20 | 20 | 20 | 21 | 21 |
| | 1000 | 21 | 21 | 23 | 23 | 23 | 24 | 24 |
| | 500 | 24 | 24 | 26 | 26 | 26 | 27 | 27 |
| | 200 | 27 | 27 | 29 | 29 | 29 | 30 | 30 |
| | 100 | 30 | 30 | 31 | 31 | 32 | 33 | 33 |
| | 50 | 32 | 33 | 34 | 34 | 35 | 36 | 36 |
| | 20 | 35 | 36 | 38 | 38 | 40 | 40 | 40 |

Large choice of reduction ratios!
Up to 36:1

DISCOUNTS

| Qty. | 1+ | 2+ | 4+ | 6+ |
|------------|------|------|------------|----|
| Disc. List | -15% | -20% | On request | |

| Part number | Ratios | Max. input speed (rpm) | Max. output speed (rpm) | Efficiency at 1000 rpm | Module | Direction of input/output rotation | Price each |
|-----------------|------------|---------------------------------|-------------------------|------------------------|--------|------------------------------------|------------|
| NT92-10 NH92-10 | 10:1 | 3000 | 300 | 84% | Same | 787,90 € | On request |
| NT92-12 NH92-12 | 12:1 | 3000 | 250 | 84% | Same | 787,90 € | |
| NT92-15 NH92-15 | 15:1 | 3000 | 200 | 84% | Same | 787,90 € | |
| NT92-18 NH92-18 | 18:1 | 3000 | 166 | 84% | Same | 787,90 € | |
| NT92-20 NH92-20 | 20:1 | 3000 | 150 | 84% | Same | 787,90 € | |
| NT92-27 NH92-27 | 27:1 | 3000 | 125 | 84% | Same | 787,90 € | |
| NT92-36 NH92-36 | 36:1 | 3000 | 83 | 84% | Same | 787,79 € | |
| NT92-SP NH92-SP | 1:1 - 36:1 | Special ratios from 1:1 to 36:1 | | | | 896,20 € | |

Dimensions in mm

Altri prodotti...



BABtss
Perno autobloccante
inox 303, Inox 303



GGP
Vite ad alette,
Tecnopolimero con
inserto in inox



BIM
Pistoncino a molla,
miniatura



TK_UUQP
Manicotto a sfere
autoallineante
Topball,
Autoallineante Topball



PRF_ROUL
Ruota per profili
alluminio, Senza freno



SA_SAKH
Supporto per
manicotto, Chiuso -
carico leggero



BOXdh
Box kit di spine
cilindriche DIN6325,
Box kit - standard DIN
6325



TBEBASE10
Economic mini-table
with trapezoidal
leadscrew, 1kg



BABV
Ball lock pins lockable
, Stainless steel



EHD16
Riduttore coassiale,
da 210 a 380 Nm



BUT
Accessori per
pannello, Arresto per



WW20
Carrello Drylin® W,
Carrello

Prodotti correlati



NT91
Riduttore coassiale a
treni paralleli, da 10 a
35 Nm - a treni paral...



NT121
Riduttore coassiale a
treni paralleli, da 20 a
68 Nm - a treni paral...