

Material

- Screw : steel (class 10.9)
- Tip : brass


Info.

The tip is fitted into the screw.
These screws are designed to lock or gently hold screws, axles, shafts or other components with a high quality surface finish.



NEW!


Brass tip

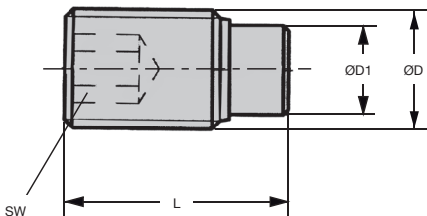

DISCOUNTS

Qty	1+	20+	30+	40+	60+	100+	300+
Disc.	Prix	-10%	-15%	-20%	-25%	-45%	On request

Part number	ØD	ØD1	L	SW	Price each. 1 to 19
NTM4-6/BR	M4	2,5	6,5	2	5,47 €
NTM4-10/BR	M4	2,5	10,5	2	5,47 €
NTM4-16/BR	M4	2,5	16,5	2	5,65 €
NTM4-30/BR	M4	2,5	30,5	2	7,60 €
NTM4-40/BR	M4	2,5	40,5	2	7,74 €
NTM5-8/BR	M5	3	8,5	2,5	4,91 €
NTM5-12/BR	M5	3	12,5	2,5	4,91 €
NTM5-20/BR	M5	3	20,5	2,5	5,15 €
NTM5-30/BR	M5	3	30,5	2,5	7,74 €
NTM5-40/BR	M5	3	40,5	2,5	7,84 €

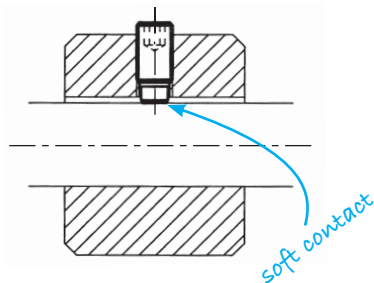

Part number	ØD	ØD1	L	SW	Price each. 1 to 19
NTM6-11/BR	M6	4,0	11,5	3	4,91 €
NTM6-17/BR	M6	4,0	17,5	3	4,91 €
NTM6-26/BR	M6	4,0	26,5	3	5,15 €
NTM6-41/BR	M6	4,0	41,5	3	7,89 €
NTM6-51/BR	M6	4,0	51,5	3	8,02 €
NTM6-61/BR	M6	4,0	61,5	3	8,06 €
NTM8-12/BR	M8	5,5	12,0	4	5,10 €
NTM8-22/BR	M8	5,5	22,0	4	5,10 €
NTM8-32/BR	M8	5,5	32,0	4	5,24 €
NTM8-52/BR	M8	5,5	52,0	4	8,17 €
NTM8-62/BR	M8	5,5	62,0	4	8,30 €
NTM8-82/BR	M8	5,5	82,0	4	8,35 €
NTM10-14/BR	M10	7,0	14,0	5	5,80 €
NTM10-18/BR	M10	7,0	18,0	5	5,80 €
NTM10-27/BR	M10	7,0	27,0	5	5,97 €
NTM10-37/BR	M10	7,0	37,0	5	6,30 €
NTM10-52/BR	M10	7,0	52,0	5	8,30 €
NTM10-62/BR	M10	7,0	62,0	5	8,44 €
NTM10-82/BR	M10	7,0	82,0	5	8,58 €
NTM12-18/BR	M12	8,5	18,5	6	6,44 €
NTM12-22/BR	M12	8,5	22,5	6	6,44 €
NTM12-32/BR	M12	8,5	32,5	6	6,96 €
NTM12-42/BR	M12	8,5	42,5	6	7,50 €
NTM12-52/BR	M12	8,5	52,5	6	8,44 €
NTM12-62/BR	M12	8,5	62,5	6	8,62 €
NTM12-82/BR	M12	8,5	82,5	6	8,86 €

Altri prodotti...



M2

Coppia ruota e vite senza fine, Acciaio non temprato




BZY_SS

Antivibrante elastico cilindrico inox, Inox




PPD

Pistoncino a molla, Per lamiera

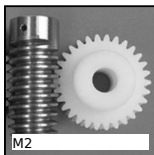

M2

Coppia ruota e vite senza fine, Plastica lavorata (delrin)

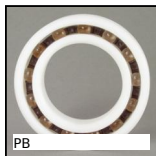

PB

Cuscinetto in plastica, Plastica - materiale sfere : vetro




S4

Pignone a catena - Inox, 4mm



DEP

Attrezzi Hygienic Usit® and Hygienic Design®, Inserto di protezione...

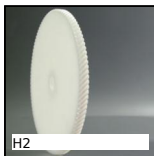

H2

Ingranaggio elicoidale ad assi incrociati a 90°, Plastica lavorata ...



WW16

Carrello Drylin® W, Carrello



RAG-12-M8

Guida di scorrimento a rotelle, Sistema di ancoraggio



E60B

Riduttore a rinvio angolare, da 4.50 a 24 Nm



PRF-SCREEN-5

Screen support, Support with 5 axes of rotation

Prodotti correlati



NTMdl

Grano punta in delrin, punta in delrin



NTM

Grano punta in nylon, punta in nylon