

## NTM<sub>DL</sub>

## Blackened steel finish

### Material

- Screw : steel (class 10.9)
- Tip : Delrin


### Info.

The tip is fitted into the screw.  
These screws are designed to lock or gently hold screws, axles, shafts or other components with a high quality surface finish.



**NEW !**


Delrin tip

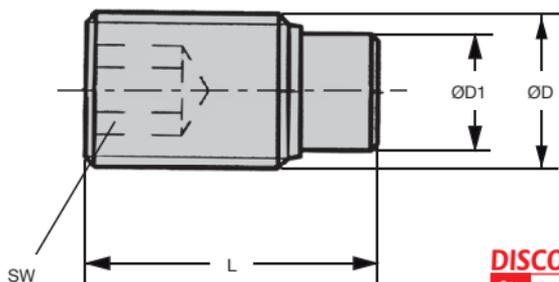

### DISCOUNTS

Qty	1+	20+	30+	40+	60+	100+	300+
Disc. Prix	-10%	-15%	-20%	-25%	-45%	On request	

Part number	ØD	ØD1	L	SW	Price each 1 to 19
NTM4-7/DL	M4	2	7	2	2,78 €
NTM4-9/DL	M4	2	9	2	2,78 €
NTM4-11/DL	M4	2	11	2	2,78 €
NTM4-13/DL	M4	2	13	2	2,78 €
NTM4-17/DL	M4	2	17	2	2,78 €
NTM4-31/DL	M4	2	31	2	6,70 €
NTM4-41/DL	M4	2	41	2	6,85 €
NTM5-9/DL	M5	3	9	2,5	2,57 €
NTM5-11/DL	M5	3	11	2,5	2,57 €
NTM5-13/DL	M5	3	13	2,5	2,57 €
NTM5-17/DL	M5	3	17	2,5	2,57 €
NTM5-21/DL	M5	3	21	2,5	2,78 €
NTM5-31/DL	M5	3	31	2,5	7,21 €
NTM5-41/DL	M5	3	41	2,5	7,32 €

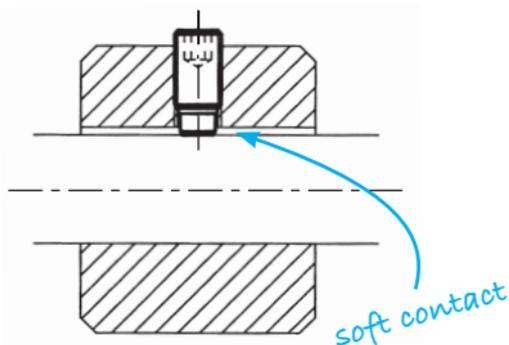

Part number	ØD	ØD1	L	SW	Price each 1 to 19
NTM6-11/DL	M6	3,5	11,3	3	2,57 €
NTM6-13/DL	M6	3,5	13,3	3	2,57 €
NTM6-17/DL	M6	3,5	17,3	3	2,78 €
NTM6-21/DL	M6	3,5	21,3	3	2,78 €
NTM6-26/DL	M6	3,5	26,3	3	2,92 €
NTM6-41/DL	M6	3,5	41,3	3	7,37 €
NTM6-51/DL	M6	3,5	51,3	3	7,51 €
NTM6-61/DL	M6	3,5	61,3	3	7,57 €
NTM8-13/DL	M8	5	13,6	4	2,92 €
NTM8-17/DL	M8	5	17,6	4	2,92 €
NTM8-21/DL	M8	5	21,6	4	2,97 €
NTM8-26/DL	M8	5	26,6	4	3,19 €
NTM8-33/DL	M8	5	33,6	4	3,60 €
NTM8-51/DL	M8	5	51,6	4	7,21 €
NTM8-61/DL	M8	5	61,6	4	7,32 €
NTM8-81/DL	M8	5	81,6	4	7,37 €
NTM10-18/DL	M10	6,5	17,9	5	3,49 €
NTM10-22/DL	M10	6,5	21,9	5	3,60 €
NTM10-27/DL	M10	6,5	26,9	5	3,66 €
NTM10-34/DL	M10	6,5	33,9	5	4,22 €
NTM10-42/DL	M10	6,5	41,9	5	4,84 €
NTM10-52/DL	M10	6,5	51,9	5	7,32 €
NTM10-62/DL	M10	6,5	61,9	5	7,42 €
NTM10-82/DL	M10	6,5	81,9	5	7,51 €
NTM12-22/DL	M12	8	22,1	6	4,06 €
NTM12-27/DL	M12	8	27,1	6	4,22 €
NTM12-34/DL	M12	8	34,1	6	4,59 €
NTM12-42/DL	M12	8	42,1	6	5,16 €
NTM12-52/DL	M12	8	52,1	6	5,92 €
NTM12-62/DL	M12	8	62,1	6	7,57 €
NTM12-82/DL	M12	8	82,1	6	7,73 €

## Altri prodotti...




FBL4004\_K32

Spazzola al metro,  
Polipropilene nero  
striato (PP)



NANO

Variatore di velocità  
3A, 3 A

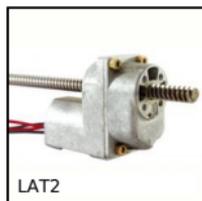

LAT2

Attuatore lineare a  
motore 2A, 2 ampere



GGB

Dado ad alette,  
Maschiato passante



PRF\_BM

Elementi di  
ancoraggio, Fissaggio  
centrale per piede



SH1

Ingranaggio elicoidale  
ad assi paralleli,  
Acciaio 20NCD2



MACss

Moschettone inox,  
Inox



PTA50ssEB

Piede snodato con  
base stampata Ø50,  
4000N



PLM-SC

Magnete piatto, With  
threaded hole




GPB

Impugnatura sferica,  
Con inserto ottone



TBV

Tavola di  
posizionamento

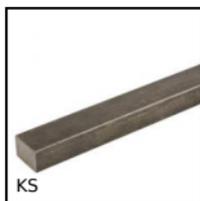

KS

Chiavetta in barre,  
Acciaio - in barre

## Prodotti correlati



NTMbr

Grano punta in  
ottone, punta in  
ottone



NTM

Grano punta in nylon,  
punta in nylon