

NTM_{DL}

Blackened steel finish

Material

- Screw : steel (class 10.9)
- Tip : Delrin


Info.

The tip is fitted into the screw.
These screws are designed to lock or gently hold screws, axles, shafts or other components with a high quality surface finish.



NEW !


Delrin tip

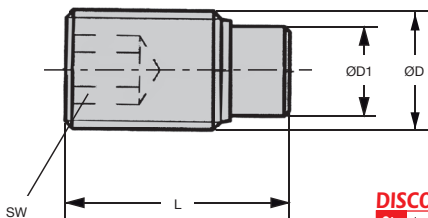

DISCOUNTS

Qty	1+	20+	30+	40+	60+	100+	300+
Disc. Prix	-10%	-15%	-20%	-25%	-45%	On request	

Part number	ØD	ØD1	L	SW	Price each 1 to 19
NTM4-7/DL	M4	2	7	2	2,78 €
NTM4-9/DL	M4	2	9	2	2,78 €
NTM4-11/DL	M4	2	11	2	2,78 €
NTM4-13/DL	M4	2	13	2	2,78 €
NTM4-17/DL	M4	2	17	2	2,78 €
NTM4-31/DL	M4	2	31	2	6,70 €
NTM4-41/DL	M4	2	41	2	6,85 €
NTM5-9/DL	M5	3	9	2,5	2,57 €
NTM5-11/DL	M5	3	11	2,5	2,57 €
NTM5-13/DL	M5	3	13	2,5	2,57 €
NTM5-17/DL	M5	3	17	2,5	2,57 €
NTM5-21/DL	M5	3	21	2,5	2,78 €
NTM5-31/DL	M5	3	31	2,5	7,21 €
NTM5-41/DL	M5	3	41	2,5	7,32 €

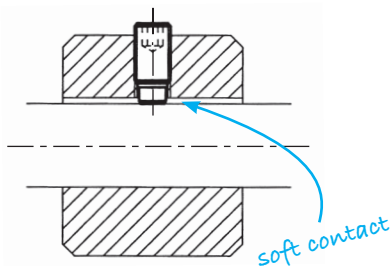

Part number	ØD	ØD1	L	SW	Price each 1 to 19
NTM6-11/DL	M6	3,5	11,3	3	2,57 €
NTM6-13/DL	M6	3,5	13,3	3	2,57 €
NTM6-17/DL	M6	3,5	17,3	3	2,78 €
NTM6-21/DL	M6	3,5	21,3	3	2,78 €
NTM6-26/DL	M6	3,5	26,3	3	2,92 €
NTM6-41/DL	M6	3,5	41,3	3	7,37 €
NTM6-51/DL	M6	3,5	51,3	3	7,51 €
NTM6-61/DL	M6	3,5	61,3	3	7,57 €
NTM8-13/DL	M8	5	13,6	4	2,92 €
NTM8-17/DL	M8	5	17,6	4	2,92 €
NTM8-21/DL	M8	5	21,6	4	2,97 €
NTM8-26/DL	M8	5	26,6	4	3,19 €
NTM8-33/DL	M8	5	33,6	4	3,60 €
NTM8-51/DL	M8	5	51,6	4	7,21 €
NTM8-61/DL	M8	5	61,6	4	7,32 €
NTM8-81/DL	M8	5	81,6	4	7,37 €
NTM10-18/DL	M10	6,5	17,9	5	3,49 €
NTM10-22/DL	M10	6,5	21,9	5	3,60 €
NTM10-27/DL	M10	6,5	26,9	5	3,66 €
NTM10-34/DL	M10	6,5	33,9	5	4,22 €
NTM10-42/DL	M10	6,5	41,9	5	4,84 €
NTM10-52/DL	M10	6,5	51,9	5	7,32 €
NTM10-62/DL	M10	6,5	61,9	5	7,42 €
NTM10-82/DL	M10	6,5	81,9	5	7,51 €
NTM12-22/DL	M12	8	22,1	6	4,06 €
NTM12-27/DL	M12	8	27,1	6	4,22 €
NTM12-34/DL	M12	8	34,1	6	4,59 €
NTM12-42/DL	M12	8	42,1	6	5,16 €
NTM12-52/DL	M12	8	52,1	6	5,92 €
NTM12-62/DL	M12	8	62,1	6	7,57 €
NTM12-82/DL	M12	8	82,1	6	7,73 €

Altri prodotti...



SSB
Ingranaggio conico
inox, 1:1



ADL_F
Anello di
sollevamento, Acciaio



AT5M AT10M
Cinghia aperta al
metro tipo AT, AT10
Poliuretano armatura
in acciaio



VPSS
Volantino a 6 lobi,
Duroplast - Inox



GG2
Ingranaggio dritto
rettificato, Acciaio
trattato



PRF_BV
Blocchetto di
fissaggio, Aggiunta e
fissaggio di pannelli



RDERSS
Tenditore, a serraggio
manuale inox



CHAFR
Cerniera, A frizione
manuale



BFM2
Dado trapezoidale,
Bronzo - 2 filetti



BPLF
Sfera portante alta
sporgenza, Leggero



SHN
Dado esagonale -
DIN934, Acciaio (Class
6/8)



PR40
Piede fissabile con
snodo - poliammide, Ø
40

Prodotti correlati



NTMbr
Grano punta in
ottone, punta in
ottone



NTM
Grano punta in nylon,
punta in nylon