

Digital position indicator

Size **XS** New

OP2



3 digit display

- 3 digit display (red digit displays tenths), displays up to 999
- Shaft driven position indicator
- 3 digit display to display and control a linear movement (or an angle) that is driven by a rotating control shaft.
- Non-flammable shock-proof technopolymer housing
- Ingress protection: IP64
- Max temperature: 80 °C
- Height of digits: 6 mm with magnifying lens
- Bore for shaft 30H7, other diameters will require reducing sleeve
- Offset of anti rotation pin: 18 mm
- Internal and external metal parts are stainless steel



Miniature

Dust seal

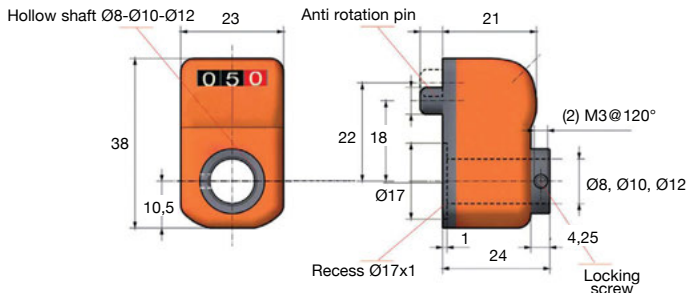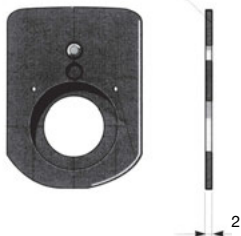

Mounting

- Insert the indicator over the shaft ensuring that the anti-rotation pin is inserted into the 6 mm hole drilled previously. Set the display to its initial reading (zero) and tighten the locking screw

Bore diameter

- Bores of 8, 10 and 12 mm are available.
- For an 8 or 10 mm bore, replace 12R in the Par N° with 8R or 10R



Display



View A



SX

DX



View B

DISCOUNTS

Qty	1+	5+	10+	15+	25+
Disc.	List	-6%	-12%	-20%	On request

Part number	View	Pitch (mm)	Display after 1 revolution (mm)	Max speed (rpm)	Counting direction	Price each 1 to 4
OP2-A10-DX-12R	A	1	01 0	800	clockwise	92,70 €
OP2-A20-DX-12R	A	2	02 0	350	clockwise	92,70 €
OP2-A30-DX-12R	A	3	03 0	250	clockwise	92,70 €
OP2-A40-DX-12R	A	4	04 0	200	clockwise	92,70 €
OP2-A50-DX-12R	A	5	05 0	150	clockwise	92,70 €
OP2-B10-DX-12R	B	1	01 0	800	clockwise	92,70 €
OP2-B20-DX-12R	B	2	02 0	350	clockwise	92,70 €
OP2-B30-DX-12R	B	3	03 0	250	clockwise	92,70 €
OP2-B40-DX-12R	B	4	04 0	200	clockwise	92,70 €
OP2-B50-DX-12R	B	5	05 0	150	clockwise	92,70 €
OP2-A10-SX-12R	A	1	01 0	800	anti-clockwise	92,70 €
OP2-A20-SX-12R	A	2	02 0	350	anti-clockwise	92,70 €
OP2-A30-SX-12R	A	3	03 0	250	anti-clockwise	92,70 €
OP2-A40-SX-12R	A	4	04 0	200	anti-clockwise	92,70 €
OP2-A50-SX-12R	A	5	05 0	150	anti-clockwise	92,70 €
OP2-B10-SX-12R	B	1	01 0	800	anti-clockwise	92,70 €
OP2-B20-SX-12R	B	2	02 0	350	anti-clockwise	92,70 €
OP2-B30-SX-12R	B	3	03 0	250	anti-clockwise	92,70 €
OP2-B40-SX-12R	B	4	04 0	200	anti-clockwise	92,70 €
OP2-B50-SX-12R	B	5	05 0	150	anti-clockwise	92,70 €

Dimensions in mm

Altri prodotti...




BSM_LOK

Pressore a molla con esagono incassato, LONG-LOK - corpo e spina ino...



CHML50

Riduttore a ruota e vite senza fine, fino a 107 Nm - Con limitatore ...

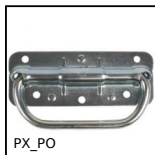

PX_PO

Maniglia - movimentazione manuale, con piastra posteriore



BUT

Accessori per pannello, Arresto per pannello



SRG

Chiusura a leva regolabile, Corsa da 117,4mm a 128mm



RURt

Ruota girevole a foro centrale, Poliuretano - Mozzo alluminio (Ultra...



NSR

Connettore rinvio d'angolo, Regolabile



P40

Riduttore a ruota e vite senza fine, fino a 118 Nm



LACT_SS

Leva a camma regolabile, Maschio



MF

Deceleratore, Flangia rettangolare



BPM_LOK

Pressore a molla con intaglio e puntale a sfera, LONG-LOK - Inox 303



BAG-MI

Anello di serraggio con intaglio e maniglia a leva, Acciaio

Prodotti correlati



EP7

Indicatore di posizione elettronico, 5 cifre



LFM

Vite trapezoidale acciaio, Acciaio semiduro - 1 filetto



SHA_PTR

Volantino pieno, Poliammide