

Articulated foot with sheet metal base Ø100

PAMF100 Max load: 15,000N
Rubber sole in EPDM, blue



- **Articulated adjustable levelling feet**
- Axial articulation +/- 10°
- With non-slip sole in EPDM Blue
- Stainless steel in shiny finish
- **Materials:**
 - Base: shiny 304 stainless steel sheet
 - Thread: 304 stainless steel, supplied without nut
 - Sole: EPDM blue

Options

- Other thread dimensions on request
- 316 grade Stainless steel on request

Advantages

- Hygienic special pad for easy cleaning.
- Food processing, Pharmaceutical and Chemical Environment

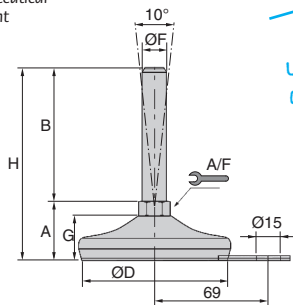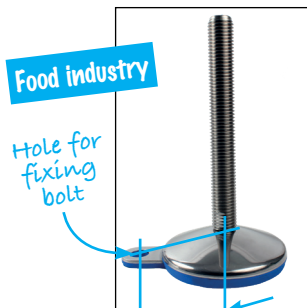

DISCOUNTS

Qty	1+	6+	10+	15+	20+
Disc. Price	-5%	-10%	-10%	-15%	On request

References	Threading		B	A	A/F	G	H	Static load(N)	Price per unit 1 to 5
	ØD	ØF							
PAMF100-16-100/EB	100	M16	100	39.5	13	30	139.5	15000	53,37€
PAMF100-16-150/EB	100	M16	150	39.5	13	30	189.5	15000	54,99€
PAMF100-16-200/EB	100	M16	200	39.5	13	30	239.5	15000	58,69€
PAMF100-20-100/EB	100	M20	100	43.0	17	30	143.0	15000	56,55€
PAMF100-20-150/EB	100	M20	150	43.0	17	30	193.0	15000	59,76€
PAMF100-20-200/EB	100	M20	200	43.0	17	30	243.0	15000	63,46€

* Depending on availability - Dimensions in mm

Our other products




TB_ECO

Bevel gear - Steel
C43, 3:1



PAMF80

Articulated fixable
foot with pressed
base, Ø 80

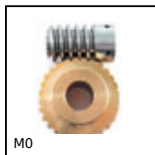

M0

Wheel, Bronze



PCS62SS

Chain sprocket -
Stainless steel,
15.875mm (DIN
08B-1)



VEL

Self-gripping cable
strip,



INS

Self tapping insert,
Steel



BLHB30

Right angled gearbox,
up to 4.47 Nm



RTE

Rotex®, flexible, cast
iron



PX_PO

Carry handle,
standard




GE1006

Flexible toggle latch,
Hooks into a slot



HK

Linear ball slide -
Stainless steel balls,
Manual locking clamp

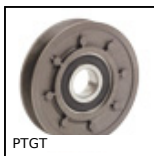

PTGT

Tensioner pulley, For
V belts

Complementary products



PTA50ssEB

Articulated foot with
sheet metal base,
Articulated foot



PTA80ssEB

Articulated foot with
sheet metal base,
Articulated foot



PTA100ssEB

Articulated foot with
sheet metal base,
Articulated foot



PAMF80EB

Articulated foot with
sheet metal base,
Articulated foot

Altri prodotti...



GAL 42

Rullo per trasportatore, Senza cuscinetti a sfere



G-ECO15

Ingranaggio dritto acciaio - serie ECO, Acciaio C45



CHAR

Cerniera a molla, avvitabile



TCXR

Tenditore per catena automatico, Con pignone acciaio



G0

Ingranaggio dritto acciaio, Acciaio 20NCD2




CDPC

Boccola di posizionamento, Acciaio



E40

Riduttore a rinvio angolare, da 2.30 a 20 Nm

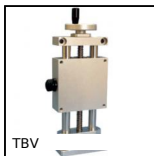

7BV

Tavola di posizionamento verticale manuale, 7kg



PGR

Impugnatura cilindrica libera retraibile, Retraibile



GE_ES

Snodo sferico, acciaio/acciaio



BEAB

Manopola, stella, anti-bacterial



VTAP

Vite a testa magnetica, Con rivestimento in gomma

Prodotti correlati



PTA50ssEB

Piede snodato con base stampata Ø50, 4000N



PTA80ssEB

Piede snodato con base stampata Ø80, 10000N



PTA100ssEB

Piede snodato con base stampata Ø100, 15000N



PAMF80EB

Piede snodato con base stampata fissabile Ø80, Piede snodato