

Articulated foot with sheet metal base Ø100

PAMF100 Max load: 15,000N
Rubber sole in EPDM, blue



- **Articulated adjustable levelling feet**
- Axial articulation +/- 10°
- With non-slip sole in EPDM Blue
- Stainless steel in shiny finish
- Materials:
 - Base: shiny 304 stainless steel sheet
 - Thread: 304 stainless steel, supplied without nut
 - Sole: EPDM blue

Options

- Other thread dimensions on request
- 316 grade Stainless steel on request

Advantages

- Hygienic special pad for easy cleaning.
- Food processing, Pharmaceutical and Chemical Environment

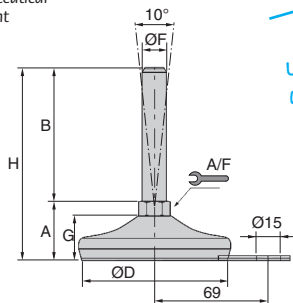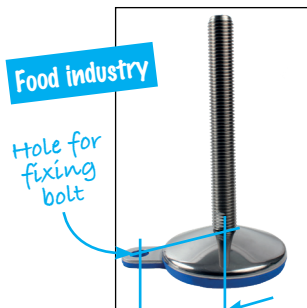

DISCOUNTS

| | | | | | |
|-------------|-----|------|------|------|------------|
| Qty | 1+ | 6+ | 10+ | 15+ | 20+ |
| Disc. Price | -5% | -10% | -10% | -15% | On request |

| References | Threading | | B | A | A/F | G | H | Static load(N) | Price per unit 1 to 5 |
|-------------------|-----------|-----|-----|------|-----|----|-------|----------------|-----------------------|
| | ØD | ØF | | | | | | | |
| PAMF100-16-100/EB | 100 | M16 | 100 | 39.5 | 13 | 30 | 139.5 | 15000 | 53,37€ |
| PAMF100-16-150/EB | 100 | M16 | 150 | 39.5 | 13 | 30 | 189.5 | 15000 | 54,99€ |
| PAMF100-16-200/EB | 100 | M16 | 200 | 39.5 | 13 | 30 | 239.5 | 15000 | 58,69€ |
| PAMF100-20-100/EB | 100 | M20 | 100 | 43.0 | 17 | 30 | 143.0 | 15000 | 56,55€ |
| PAMF100-20-150/EB | 100 | M20 | 150 | 43.0 | 17 | 30 | 193.0 | 15000 | 59,76€ |
| PAMF100-20-200/EB | 100 | M20 | 200 | 43.0 | 17 | 30 | 243.0 | 15000 | 63,46€ |

* Depending on availability - Dimensions in mm

Our other products




TB_ECO

Bevel gear - Steel
C43, 3:1



PAMF80

Articulated fixable
foot with pressed
base, Ø 80

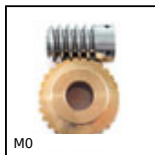

M0

Wheel, Bronze



PCS625S

Chain sprocket -
Stainless steel,
15.875mm (DIN
08B-1)



VEL

Self-gripping cable
strip,



INS

Self tapping insert,
Steel



BLHB30

Right angled gearbox,
up to 4.47 Nm



RTE

Rotex®, flexible, cast
iron



PX_PO

Carry handle,
standard



GE1006

Flexible toggle latch,
Hooks into a slot



HK

Linear ball slide -
Stainless steel balls,
Manual locking clamp



PTGT

Tensioner pulley, For
V belts

Complementary products



PTA50ssEB

Articulated foot with
sheet metal base,
Articulated foot



PTA80ssEB

Articulated foot with
sheet metal base,
Articulated foot



PTA100ssEB

Articulated foot with
sheet metal base,
Articulated foot



PAMF80EB

Articulated foot with
sheet metal base,
Articulated foot

Altri prodotti...



T5-BAR

Barra dentata, T5



ZDB

Ingranaggio conico in
plastica, 2:1



G0

Ingranaggio dritto
acciaio, Acciaio
20NCD2



BABA

Perno autobloccante,
Acciaio



DOMI30

Kit di raccordo, Kit di
raccordo XY



UGH20

Unità di guida tipo H,
Per martinetti Ø20



RFV63

Riduttore inox a ruota
e vite senza fine, fino
a 152 Nm



P40

Riduttore a ruota e
vite senza fine, fino a
118 Nm



TB_ECO

Ingranaggio conico -
Acciaio C43 - ECO, 3:1



CHM30-MOT

Motoriduttore AC
asincrono da 0,09 a



CHAE4060PA

Cerniera ad avvitare
estetica asimmetrica,



CHB

Feet, For CHB gearbox

Prodotti correlati



PTA50ssEB

Piede snodato con
base stampata Ø50,
Piede snodato



PTA80ssEB

Piede snodato con
base stampata Ø80,
Piede snodato



PTA100ssEB

Piede snodato con
base stampata Ø100,
Piede snodato



PAMF80EB

Piede snodato con
base stampata
fissabile Ø80, Piede
snodato