

Articulated foot with sheet metal base Ø100

PAMF100 Max load: 15,000N
Rubber sole in EPDM, blue



- **Articulated adjustable levelling feet**
- Axial articulation +/- 10°
- With non-slip sole in EPDM Blue
- Stainless steel in shiny finish
- Materials:
 - Base: shiny 304 stainless steel sheet
 - Thread: 304 stainless steel, supplied without nut
 - Sole: EPDM blue

Options

- Other thread dimensions on request
- 316 grade Stainless steel on request

Advantages

- Hygienic special pad for easy cleaning.
- Food processing, Pharmaceutical and Chemical Environment

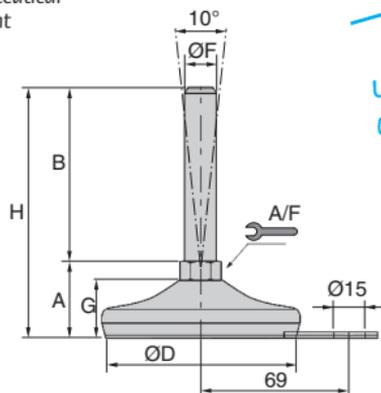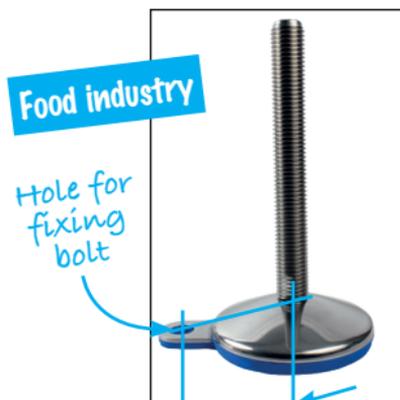

DISCOUNTS

Qty	1+	6+	10+	15+	20+
Disc.	Price	-5%	-10%	-15%	On request

References	Threading		B	A	A/F	G	H	Static load(N)	Price per unit 1 to 5
	ØD	ØF							
PAMF100-16-100/EB	100	M16	100	39.5	13	30	139.5	15000	53,37€
PAMF100-16-150/EB	100	M16	150	39.5	13	30	189.5	15000	54,99€
PAMF100-16-200/EB	100	M16	200	39.5	13	30	239.5	15000	58,69€
PAMF100-20-100/EB	100	M20	100	43.0	17	30	143.0	15000	56,55€
PAMF100-20-150/EB	100	M20	150	43.0	17	30	193.0	15000	59,76€
PAMF100-20-200/EB	100	M20	200	43.0	17	30	243.0	15000	63,46€

* Depending on availability - Dimensions in mm

Our other products



TB_ECO

Bevel gear - Steel
C43, 3:1



PAMF80

Articulated fixable
foot with pressed
base, Ø 80



M0

Wheel, Bronze



PCS625S

Chain sprocket -
Stainless steel,
15.875mm (DIN
08B-1)



VEL

Self-gripping cable
strip,



INS

Self tapping insert,
Steel



BLHB30

Right angled gearbox,
up to 4.47 Nm



RTE

Rotex®, flexible, cast
iron



PX_PO

Carry handle,
standard



GE1006

Flexible toggle latch,
Hooks into a slot



HK

Linear ball slide -
Stainless steel balls,
Manual locking clamp



PTGT

Tensioner pulley, For
V belts

Complementary products



PTA50ssEB

Articulated foot with
sheet metal base,
Articulated foot



PTA80ssEB

Articulated foot with
sheet metal base,
Articulated foot



PTA100ssEB

Articulated foot with
sheet metal base,
Articulated foot



PAMF80EB

Articulated foot with
sheet metal base,
Articulated foot

Altri prodotti...



ZG0

Ingranaggio dritto in plastica, Plastica lavorata (delrin)




MDB_MTB

Ingranaggio conico in plastica stampata, 2:1



SLBS

Pistoncino a molla, Tutto inox

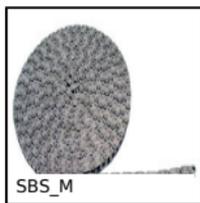

SBS_M

Catena semplice al metro, Inox



CLG3

Ingranaggio dritto in plastica stampata, Nylon stampato



RFK58C

Riduttore ipoide inox, fino a 500 Nm



BPL

Sfera portante con flangia, Leggero



PRF_ROUL

Ruota per profili alluminio, Senza freno



YG1

Ingranaggio dritto PRESTAZIONE, Acciaio 35NCD6



BABPass

Perno autobloccante inox temprato ad anello, Con



BABpss

Perno autobloccante, Inox



PR125

Piede fissabile con snodo - poliammide, Ø 123

Prodotti correlati



PTA50ssEB

Piede snodato con base stampata Ø50, 4000N



PTA80ssEB

Piede snodato con base stampata Ø80, 10000N



PTA100ssEB

Piede snodato con base stampata Ø100, 15000N



PAMF80EB

Piede snodato con base stampata fissabile Ø80, Piede snodato