

Articulated foot with sheet metal base Ø100

PAMF100

Max load: 15,000N
Rubber sole in EPDM, blue



- **Articulated adjustable levelling feet**
- Axial articulation +/- 10°
- With non-slip sole in EPDM Blue
- Stainless steel in shiny finish
- Materials:
 - Base: shiny 304 stainless steel sheet
 - Thread: 304 stainless steel, supplied without nut
 - Sole: EPDM blue

Options

- Other thread dimensions on request
- 316 grade Stainless steel on request

Advantages

- Hygienic special pad for easy cleaning.
- Food processing, Pharmaceutical and Chemical Environment

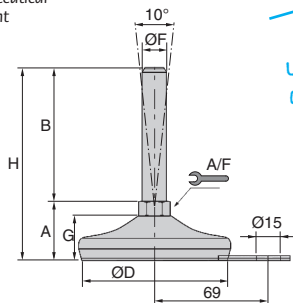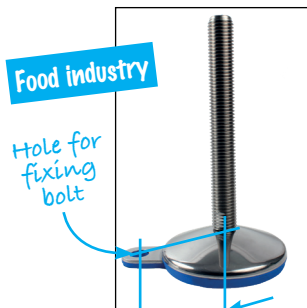

DISCOUNTS

Qty	1+	6+	10+	15+	20+
Disc. Price	-5%	-10%	-10%	-15%	On request

References	Threading		B	A	A/F	G	H	Static load(N)	Price per unit 1 to 5
	ØD	ØF							
PAMF100-16-100/EB	100	M16	100	39.5	13	30	139.5	15000	53,37€
PAMF100-16-150/EB	100	M16	150	39.5	13	30	189.5	15000	54,99€
PAMF100-16-200/EB	100	M16	200	39.5	13	30	239.5	15000	58,69€
PAMF100-20-100/EB	100	M20	100	43.0	17	30	143.0	15000	56,55€
PAMF100-20-150/EB	100	M20	150	43.0	17	30	193.0	15000	59,76€
PAMF100-20-200/EB	100	M20	200	43.0	17	30	243.0	15000	63,46€

* Depending on availability - Dimensions in mm

Our other products



TB_ECO

Bevel gear - Steel
C43, 3:1



PAMF80

Articulated fixable
foot with pressed
base, Ø 80



M0

Wheel, Bronze



PCS62SS

Chain sprocket -
Stainless steel,
15.875mm (DIN
08B-1)



VEL

Self-gripping cable
strip,



INS

Self tapping insert,
Steel



BLHB30

Right angled gearbox,
up to 4.47 Nm



RTE

Rotex®, flexible, cast
iron



PX_PO

Carry handle,
standard




GE1006

Flexible toggle latch,
Hooks into a slot



HK

Linear ball slide -
Stainless steel balls,
Manual locking clamp

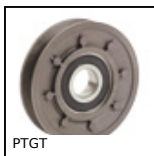

PTGT

Tensioner pulley, For
V belts

Complementary products



PTA50ssEB

Articulated foot with
sheet metal base,
Articulated foot



PTA80ssEB

Articulated foot with
sheet metal base,
Articulated foot



PTA100ssEB

Articulated foot with
sheet metal base,
Articulated foot



PAMF80EB

Articulated foot with
sheet metal base,
Articulated foot

Altri prodotti...



SF_ZZ
Cuscinetto radiale a sfere, Inox



ACL
Elementi di giunzione, Angolare semicircolare



BSPT
Morsetto per guide, Rondo



G-ECO
Ingranaggio dritto acciaio - serie ECO, Acciaio C45



PCS50K
Pignone a catena dentatura temprata, 12.7mm (DIN08B-1)



ACLEPP
Angolare, 4 fori




PRF_GAL
Rotella per profilo alluminio, Rotella cava $\varnothing 12$



HW_HT
Guida su semi-binari, Binario



ZBconique
Ingranaggio conico in plastica, 1:1

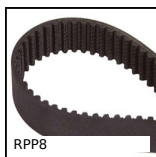

RPP8
Cinghia di trasmissione RPP, RPP8



J52
Riduttore coassiale a treni paralleli, da 0.27 a 0.90 - a treni para...



BPM
Pressore a molla con intaglio e puntale a sfera, Acciaio

Prodotti correlati



PTA50ssEB
Piede snodato con base stampata $\varnothing 50$, Piede snodato



PTA80ssEB
Piede snodato con base stampata $\varnothing 80$, Piede snodato



PTA100ssEB
Piede snodato con base stampata $\varnothing 100$, Piede snodato



PAMF80EB
Piede snodato con base stampata fissabile $\varnothing 80$, Piede snodato