



Articulated foot with sheet metal base Ø80

Max load: 10,000N
Rubber sole in EPDM, blue

PAMF80

- Articulated adjustable levelling feet
- Axial articulation +/- 10°
- With non-slip sole in EPDM Blue
- Stainless steel in shiny finish
- Materials:
 - Base: shiny 304 stainless steel sheet
 - Thread: 304 stainless steel, supplied without nut
 - Sole: EPDM blue

Options

- Other thread dimensions on request
- 316 grade Stainless steel on request


Advantages

- Hygienic special sole for easy cleaning.
- Food processing, Pharmaceutical and Chemical Environment

Food industry

Hole for fixing bolt

Large spacing allows use of a hammer drill

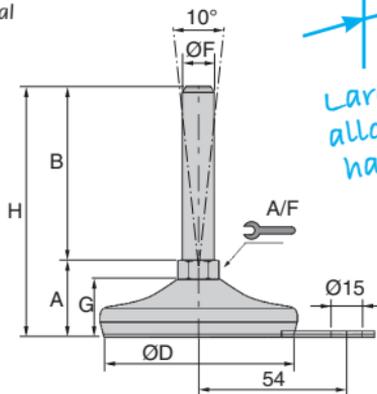


DISCOUNTS

Qty	1+	6+	10+	15+	20+
Disc. Price		-5%	-10%	-15%	On request

Part N°	ØD	ØF	B	A	A/F	G	H	Static load(N)	Price per unit 1 to 5
PAMF80-12-100/EB	80	M12	100	35	14	25	135	10000	36,75 €
PAMF80-12-150/EB	80	M12	150	35	14	25	185	10000	38,83 €
PAMF80-16-75/EB	80	M16	75	35	13	25	110	10000	37,24 €
PAMF80-16-125/EB	80	M16	125	35	13	25	160	10000	39,90 €
PAMF80-16-175/EB	80	M16	175	35	13	25	210	10000	42,53 €
PAMF80-20-100/EB	80	M20	100	38	17	25	138	10000	42,53 €
PAMF80-20-150/EB	80	M20	150	38	17	25	188	10000	45,16 €
PAMF80-20-200/EB	80	M20	200	38	17	25	238	10000	49,11 €

*Within the limits of available stock - Dimensions in mm

Our other products

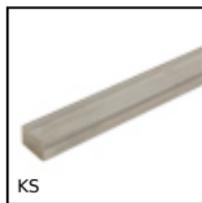

KS
Key, Stainless steel -
Keystock



PRF_GAL
Roller for aluminium
profile, Fixing kit for
roller concentric



PRF-SMA
Closing system, Easily
adjustable lock



CHTRP
Single and dual
output gearboxes, Up
to 87,3Nm



ACLRP
Wheel, Integrated
bearing



HAS
Captive C washer,
Slotted flat headed
shoulder screw



SLBW
Indexing plunger,
Weldable - Steel



SDB
Locating bolt support
bracket, Mounting
holes at 90° to
locating bolt



ESCB
Support base, Bipod
support element with
cross support



LC
Friction torque limiter,
190 to 1800 Nm



RFK48B
Hypoid gearbox -
Stainless steel, up to
350 Nm



DB
Bevel gear - Steel
60C40, 2:1

Complementary products



PTA50ssEB
Articulated foot with
sheet metal base,
Articulated foot



PTA80ssEB
Articulated foot with
sheet metal base,
Articulated foot



PTA100ssEB
Articulated foot with
sheet metal base,
Articulated foot




PAMF100EB
Articulated foot with
sheet metal base,
Articulated foot

Altri prodotti...



TCXR

Tenditore per catena automatico, Con pignone acciaio

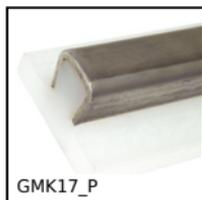

GMK17_P

Guida prodotto laterale piatta, Per imbottigliamento e imballaggio



NJM

Connettore rinvio d'angolo, Multiplo



BPM-Z

Pressore a molla con intaglio e puntale a sfera, Corpo plastica + sf...



EHD08-9

Riduttore coassiale, da 35 a 50 Nm



FHCS

Vite a testa svasata piana, Inox A2 - DIN 7991



PW_PWG1

Vite senza fine di precisione, Inox



UTKpwrr

Guida lineare Utilitrack®, Profilo guida a V



EKN

Giunto a soffietto Gerwah®, da 0.5 a



ZG1

Ingranaggio dritto in plastica, Plastica



KON

Piedino antivibrante cilindrico, Inox



NIN

Dado autofrenante, Acciaio

Prodotti correlati



PTA50ssEB

Piede snodato con base stampata Ø50, 4000N



PTA80ssEB

Piede snodato con base stampata Ø80, 10000N



PTA100ssEB

Piede snodato con base stampata Ø100, 15000N



PAMF100EB

Piede snodato con base stampata fissabile Ø100, Piede snodato