



# Articulated foot with sheet metal base Ø80

Max load: 10,000N  
Rubber sole in EPDM, blue

PAMF80

- Articulated adjustable levelling feet
- Axial articulation +/- 10°
- With non-slip sole in EPDM Blue
- Stainless steel in shiny finish
- Materials:
  - Base: shiny 304 stainless steel sheet
  - Thread: 304 stainless steel, supplied without nut
  - Sole: EPDM blue

## Options

- Other thread dimensions on request
- 316 grade Stainless steel on request


## Advantages

- Hygienic special sole for easy cleaning.
- Food processing, Pharmaceutical and Chemical Environment

Food industry

Hole for fixing bolt

Large spacing allows use of a hammer drill

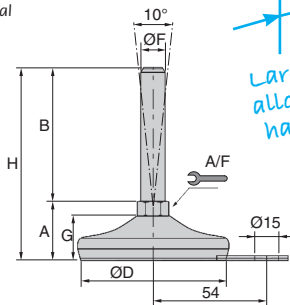


## DISCOUNTS

Qty	1+	6+	10+	15+	20+
Disc. Price		-5%	-10%	-15%	On request

Part N°	ØD	ØF	B	A	A/F	G	H	Static load(N)	Price per unit 1 to 5
PAMF80-12-100/EB	80	M12	100	35	14	25	135	10000	36,75 €
PAMF80-12-150/EB	80	M12	150	35	14	25	185	10000	38,83 €
PAMF80-16-75/EB	80	M16	75	35	13	25	110	10000	37,24 €
PAMF80-16-125/EB	80	M16	125	35	13	25	160	10000	39,90 €
PAMF80-16-175/EB	80	M16	175	35	13	25	210	10000	42,53 €
PAMF80-20-100/EB	80	M20	100	38	17	25	138	10000	42,53 €
PAMF80-20-150/EB	80	M20	150	38	17	25	188	10000	45,16 €
PAMF80-20-200/EB	80	M20	200	38	17	25	238	10000	49,11 €

\*Within the limits of available stock - Dimensions in mm

## Our other products

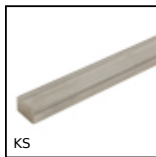

Key, Stainless steel - Keystock



Roller for aluminium profile, Fixing kit for roller concentric



Closing system, Easily adjustable lock



Single and dual output gearboxes, Up to 87,3Nm



Wheel, Integrated bearing



Captive C washer, Slotted flat headed shoulder screw



Indexing plunger, Weldable - Steel



Locating bolt support bracket, Mounting holes at 90° to locating bolt



Support base, Bipod support element with cross support



Friction torque limiter, 190 to 1800 Nm



Hypoid gearbox - Stainless steel, up to 350 Nm



Bevel gear - Steel 60C40, 2:1

## Complementary products



Articulated foot with sheet metal base, Articulated foot



Articulated foot with sheet metal base, Articulated foot



Articulated foot with sheet metal base, Articulated foot



Articulated foot with sheet metal base, Articulated foot

## Altri prodotti...



IN1  
Ingranaggio interno,  
Acciaio 20NCD2



D-PAR\_SS  
Piedino antivibrante  
parabolico, inox



PO  
Maniglia a ponte -  
Multi-settore, Foro  
cieco maschiato



AT10-BAR  
Barra dentata, AT10



VTLM  
Volantino a 3 lobi,  
Poliammide - Acciaio



WW16  
Carrello Drylin® W,  
Carrello



SH1  
Ingranaggio elicoidale  
ad assi paralleli,  
Acciaio 20NCD2



PLM-C  
Magnete piatto di  
fermo, Magnete di  
fermo piatto



GPLbr  
Scovolo, ottone



BOX-WM  
Rondella semplice -  
DIN125, Valigetta di  
rondelle acciaio



METEB  
Barre autolubrificanti,  
Bronzo BP25



LVT  
Mini martinetto  
motorizzato 1A, 1  
ampere

## Prodotti correlati



PTA50ssEB  
Piede snodato con  
base stampata Ø50,  
4000N



PTA80ssEB  
Piede snodato con  
base stampata Ø80,  
10000N



PTA100ssEB  
Piede snodato con  
base stampata Ø100,  
15000N



PAMF100EB  
Piede snodato con  
base stampata  
fissabile Ø100, Piede  
snodato