



Articulated foot with sheet metal base Ø80

Max load: 10,000N
Rubber sole in EPDM, blue

PAMF80

- Articulated adjustable levelling feet
- Axial articulation +/- 10°
- With non-slip sole in EPDM Blue
- Stainless steel in shiny finish
- Materials:
 - Base: shiny 304 stainless steel sheet
 - Thread: 304 stainless steel, supplied without nut
 - Sole: EPDM blue

Options

- Other thread dimensions on request
- 316 grade Stainless steel on request


Advantages

- Hygienic special sole for easy cleaning.
- Food processing, Pharmaceutical and Chemical Environment

Food industry

Hole for fixing bolt

Large spacing allows use of a hammer drill

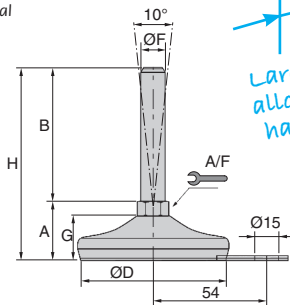


DISCOUNTS

Qty	1+	6+	10+	15+	20+
Disc. Price		-5%	-10%	-15%	On request

Part N°	ØD	ØF	B	A	A/F	G	H	Static load(N)	Price per unit 1 to 5
PAMF80-12-100/EB	80	M12	100	35	14	25	135	10000	36,75 €
PAMF80-12-150/EB	80	M12	150	35	14	25	185	10000	38,83 €
PAMF80-16-75/EB	80	M16	75	35	13	25	110	10000	37,24 €
PAMF80-16-125/EB	80	M16	125	35	13	25	160	10000	39,90 €
PAMF80-16-175/EB	80	M16	175	35	13	25	210	10000	42,53 €
PAMF80-20-100/EB	80	M20	100	38	17	25	138	10000	42,53 €
PAMF80-20-150/EB	80	M20	150	38	17	25	188	10000	45,16 €
PAMF80-20-200/EB	80	M20	200	38	17	25	238	10000	49,11 €

*Within the limits of available stock - Dimensions in mm

Our other products

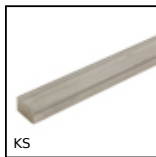

Key, Stainless steel - Keystock



Roller for aluminium profile, Fixing kit for roller concentric



Closing system, Easily adjustable lock



Single and dual output gearboxes, Up to 87,3Nm



Wheel, Integrated bearing



Captive C washer, Slotted flat headed shoulder screw



Indexing plunger, Weldable - Steel



Locating bolt support bracket, Mounting holes at 90° to locating bolt



Support base, Bipod support element with cross support



Friction torque limiter, 190 to 1800 Nm



Hypoid gearbox - Stainless steel, up to 350 Nm



Bevel gear - Steel 60C40, 2:1

Complementary products



Articulated foot with sheet metal base, Articulated foot



Articulated foot with sheet metal base, Articulated foot




Articulated foot with sheet metal base, Articulated foot



Articulated foot with sheet metal base, Articulated foot

Altri prodotti...

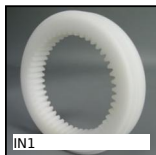

IN1

Ingranaggio interno,
Plastica lavorata
(delrin)



E15

Riduttore a rinvio
angolare, da 0.40 a
2.53 Nm



BPH

Sfera portante a
incastro cilindrico,
Forte



PRFRTR

Elementi di giunzione,
Giunto di
collegamento
trasversale



VML

Volantino a lobi, Vite
di pressione



GLB

Piccolo volano a 6
alette, Tecnopolimero
- Inox



CTZYSS

Antivibrante elastico
inox sgolato, Inox



RBG

Ruota, Rivestimento
in gomma - nucleo in
polipropilene



NPTF20

Morsetto di
collegamento,
Distanziale Ø10 a Ø14



GLT3-46

Guide telescopiche
acciaio, Estensione
totale



DOG111

Motoriduttore DC 12V
e 24V DC, da 1.5 a 6
Nm



LC

Limitatore di coppia
ad attrito, 30 a 240
Nm

Prodotti correlati



PTA50ssEB

Piede snodato con
base stampata Ø50,
Piede snodato



PTA80ssEB

Piede snodato con
base stampata Ø80,
Piede snodato



PTA100ssEB

Piede snodato con
base stampata Ø100,
Piede snodato



PAMF100EB

Piede snodato con
base stampata
fissabile Ø100, Piede
snodato