

# Articulated pressed steel feet Ø80

Ste

## PARF80

## Maximum load 20,000N

- **Swivelling mounting foot with steel mounting plate**

- **Materials:**

Base - chromed steel plate

Threaded shaft - chromed steel


### Usage

- The threaded shaft is free to rotate
- A nut under the mounting base allows both rotation and angular inclination ( $\pm 4^\circ$ ) movement to be restricted and means these feet can be used to support posts with recessed holes or mounting plates used with a nut and locknut.
- Angular blocking reduces noise and any lever effect on the mountings (avoids risk of being pulled out)

### Advantage

- Ideal for floor mounting robots and also increased speed of production

Economical

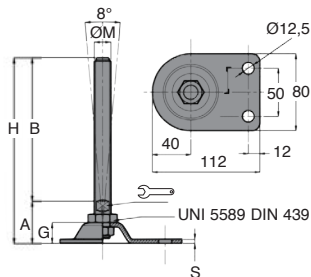

### DISCOUNTS

Qty	1+	6+	10+	15+	20+
Disc.	List	-5%	-10%	-15%	On request

Part number	ØM	B	S	A	SW	G	H	Static load (N)	Price each 1 to 5
PARF80-16-150	M16	150	3	39,5	13	19	189,5	20000	16,51 €
PARF80-16-200	M16	200	3	39,5	13	19	239,5	20000	17,63 €
PARF80-20-150	M20	150	3	40,5	17	19	190,5	20000	18,91 €
PARF80-20-200	M20	200	3	40,5	17	19	240,5	20000	20,53 €

Dimensions in mm

## Altri prodotti...



CHA35

Cerniera ad avvitare,  
Cerniera



RUrt

Ruota girevole a foro  
centrale, Poliuretano -  
Mozzo alluminio  
(Ultra...



PW\_PWG1

Vite senza fine di  
precisione, Acciaio



TMR

Tenditore rigido,  
Manuale



ZG2

Ingranaggio dritto in  
plastica, Plastica  
lavorata (delrin)



HDSS

Giunto cardanico -  
inox, Sollecitazioni  
intense



PV1R

Braccio portaventosa  
orientabile, Serraggio  
standard



BSM\_LOK

Pressore a molla con  
esagono incassato,  
LONG-LOK - corpo e  
spina in ...



Q7

Cuscinetto obliquo a  
sfere, Acciaio




PRES

Accessori per pressa  
PRES-3HR e  
PRES-4HR, Portapinz



D19 D29

Molla di compressione  
al metro acciaio, al  
metro

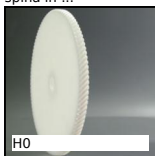

H0

Ingranaggio elicoidale  
ad assi incrociati a  
90°, Plastica lavorata  
...

## Prodotti correlati



SPIT

Piede senza snodo,  
Con foro per fissaggio



PTAF80-PAMF80

Piede fissabile con  
base lamiera Ø80, Ø  
80



PARF110

Piede senza snodo,  
Piede snodato  
oscillante fissabile  
Ø110