

Articulated pressed steel feet Ø80

Ste

PARF80

Maximum load 20,000N

- **Swivelling mounting foot with steel mounting plate**

- **Materials:**

Base - chromed steel plate

Threaded shaft - chromed steel


Usage

- The threaded shaft is free to rotate
- A nut under the mounting base allows both rotation and angular inclination ($\pm 4^\circ$) movement to be restricted and means these feet can be used to support posts with recessed holes or mounting plates used with a nut and locknut.
- Angular blocking reduces noise and any lever effect on the mountings (avoids risk of being pulled out)

Advantage

- Ideal for floor mounting robots and also increased speed of production

Economical

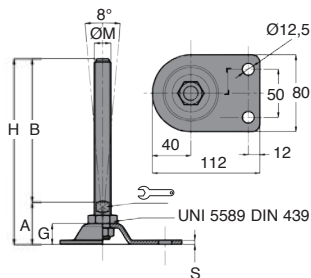

DISCOUNTS

Qty	1+	6+	10+	15+	20+
Disc.	List	-5%	-10%	-15%	On request

Part number	ØM	B	S	A	SW	G	H	Static load (N)	Price each 1 to 5
PARF80-16-150	M16	150	3	39,5	13	19	189,5	20000	16,51 €
PARF80-16-200	M16	200	3	39,5	13	19	239,5	20000	17,63 €
PARF80-20-150	M20	150	3	40,5	17	19	190,5	20000	18,91 €
PARF80-20-200	M20	200	3	40,5	17	19	240,5	20000	20,53 €

Dimensions in mm


Altri prodotti...



RBNpl
Ruota fissa con
piastra, Acciaio -
caucciù



MSP38
Inserto con piastrina a
incollare
Masterplate®,
Cilindrico Ø38 con...

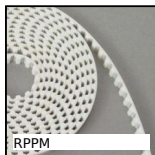

RPPM
Cinghia aperta al
metro tipo RPP, RPP5
Poliuretano armatura
in acciaio



PSG15
Ingranaggio dritto di
precisione, Inox 316



ACAss
Albero scanalato Inox
304, Inox



BPVM
Sfera portante
avvitabile miniatura,
Miniatura ad avvitare



DOMI80
Accessori di
collegamento, Piatto
girevole



SCH
Attrezzo di bloccaggio
a tirante, A tirante
orizzontale - acciaio



PRF_JL2
Panel accessories,
Guarnizione - Ø 2mm



BABTV
Ball lock pins lockable
, Stainless steel



ACL-PR
Elementi di giunzione,
Collegamento a 90°



INSTool
Boccola autofilettante
- Attrezzo, Strumento
di posa

Prodotti correlati



SPIT
Piede senza snodo,
Con foro per fissaggio



PTAF80-PAMF80
Piede fissabile con
base lamiera Ø80, Ø
80



PARF110
Piede senza snodo,
Piede snodato
oscillante fissabile
Ø110