

Articulated pressed steel feet Ø80

Ste

PARF80

Maximum load 20,000N

- **Swivelling mounting foot with steel mounting plate**

- **Materials:**

Base - chromed steel plate

Threaded shaft - chromed steel


Usage

- The threaded shaft is free to rotate
- A nut under the mounting base allows both rotation and angular inclination ($\pm 4^\circ$) movement to be restricted and means these feet can be used to support posts with recessed holes or mounting plates used with a nut and locknut.
- Angular blocking reduces noise and any lever effect on the mountings (avoids risk of being pulled out)

Advantage

- Ideal for floor mounting robots and also increased speed of production

Economical

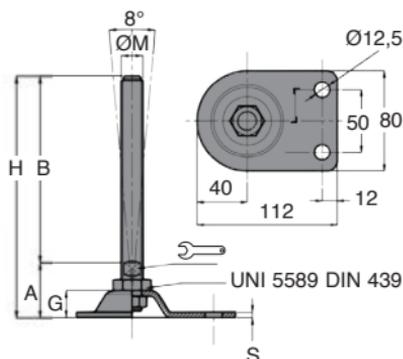


DISCOUNTS

Qty	1+	6+	10+	15+	20+
Disc.	List	-5%	-10%	-15%	On request

Part number	ØM	B	S	A	SW	G	H	Static load (N)	Price each 1 to 5
PARF80-16-150	M16	150	3	39,5	13	19	189,5	20000	16,51 €
PARF80-16-200	M16	200	3	39,5	13	19	239,5	20000	17,63 €
PARF80-20-150	M20	150	3	40,5	17	19	190,5	20000	18,91 €
PARF80-20-200	M20	200	3	40,5	17	19	240,5	20000	20,53 €

Dimensions in mm

Altri prodotti...

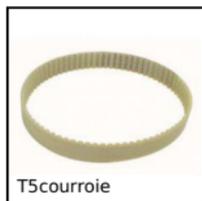


T5courroie

Cinghia di
posizionamento T, T5
Poliuretano armatura
in acciaio



BSM

Pressore a molla con
esagono incassato,
corpo in acciaio, spina
in p...

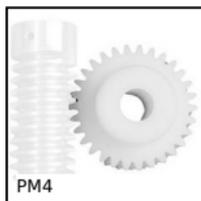

PM4

Ruota per vite senza
fine, Plastica lavorata
(delrin)



LVT

Mini martinetto
motorizzato 2A, 2
ampere



PW_PWG3

Ruota di precisione,
Bronzo



BABV

Ball lock pins lockable
, Stainless steel



SUA4

Catena semplice al
metro, Acciaio



BPL

Sfera portante con
flangia, Leggero



ZG1

Ingranaggio dritto in
plastica, Plastica



G2

Ingranaggio dritto
acciaio, Acciaio



AC144

Piastrina di riscontro
piatta per chiusura,



PSG155

Ingranaggio dritto di
precisione, Inox 303

Prodotti correlati



SPIT

Piede senza snodo,
Con foro per fissaggio



PTAF80-PAMF80

Piede fissabile con
base lamiera Ø80, Ø
80



PARF110

Piede senza snodo,
Piede snodato
oscillante fissabile
Ø110