

# Articulated pressed steel feet Ø80

Ste

## PARF80

## Maximum load 20,000N

- **Swivelling mounting foot with steel mounting plate**

- **Materials:**

Base - chromed steel plate

Threaded shaft - chromed steel


### Usage

- The threaded shaft is free to rotate
- A nut under the mounting base allows both rotation and angular inclination ( $\pm 4^\circ$ ) movement to be restricted and means these feet can be used to support posts with recessed holes or mounting plates used with a nut and locknut.
- Angular blocking reduces noise and any lever effect on the mountings (avoids risk of being pulled out)

### Advantage

- Ideal for floor mounting robots and also increased speed of production

Economical

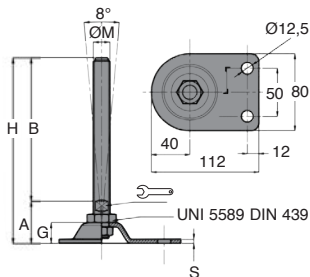

### DISCOUNTS

Qty	1+	6+	10+	15+	20+
Disc.	List	-5%	-10%	-15%	On request

Part number	ØM	B	S	A	SW	G	H	Static load (N)	Price each 1 to 5
PARF80-16-150	M16	150	3	39,5	13	19	189,5	20000	16,51 €
PARF80-16-200	M16	200	3	39,5	13	19	239,5	20000	17,63 €
PARF80-20-150	M20	150	3	40,5	17	19	190,5	20000	18,91 €
PARF80-20-200	M20	200	3	40,5	17	19	240,5	20000	20,53 €

Dimensions in mm

## Altri prodotti...



DB

Ingranaggio conico in acciaio, 2:1



TIFss

Tirante tutto filetto - DIN976A, Inox



ACL-FPA

Accessori per pannelli, Morsetto di fissaggio



GE32

Chiusura a leva rigida ad anello, Standard



SUPss

Calettatore di bloccaggio autocentrante inox, Senza ghiera



S2B

Supporto corto per manico chiuso a sfere, Chiuso - Corto



RTTss

Calettatore di bloccaggio, Coppia media/elevata



PSG15

Ingranaggio dritto di precisione, Inox 303



VCMB

Vite di giunzione metallo/legno, Acciaio



WJUM10

Pattino Drylin® W, Pattino



DBL821

Rotella per catena, Serie 821



BPLF

Sfera portante alta sporgenza, Leggero

## Prodotti correlati



SPIT

Piede senza snodo, Con foro per fissaggio



PTAF80-PAMF80

Piede fissabile con base lamiera Ø80, Ø 80



PARF110

Piede senza snodo, Piede snodato oscillante fissabile Ø110