

# Fixed anti-vibration foot mount **New**

## PAV

For loads up to 35,000 N


- **Adjustable anti-vibration floor mount**
- Fine thread for an accurate level
- **Materials:**
  - Body: Chromed sheet steel
  - Thread: Chromed steel
  - Base: Rubber NBR 80 shore

### Applications

- Machine tools, presses, injection machines, compressors.

### Info

- Supplied with 1 nut and 1 washer

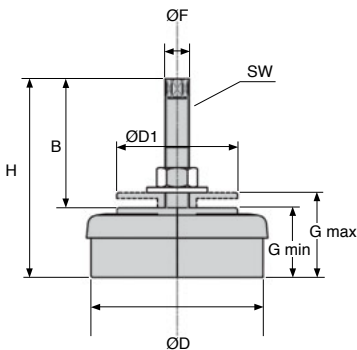

### DISCOUNTS

Qty	1+	6+	10+	15+
Disc.	List	-5%	-10%	On request

Part number	ØD	ØF	B	ØD1	SW	G	H	Max load Dynamic (N)	Max load Static (N)	Price each 1 to 5
PAV80-M12C	80	M12x1,25	87	60	8	40-50	136	2500	5000	35,18 €
PAV120-M16C	120	M16x1,5	93	80	9	45-58	150	4000	10000	59,31 €
PAV160-M20C	160	M20x1,5	125	100	12	53-65	190	9000	20000	98,01 €
PAV200-M20C	200	M20x1,5	125	130	12	69-82	207	15000	35000	134,70 €

Dimensions in mm

## Altri prodotti...



VDS CB

Bloccaggio scorrevole per la regolazione, Piastri di base per il blo...



BH01

Cuscinetto radiale flangiato, Montaggio : pressione e colla



PF30NM

Riduttore a ruota e vite senza fine, fino a 8.8 Nm



PRF\_PL\_4590

Elementi di giunzione, Piastra di giunzione - 45x90 mm



LRM

Dado cilindrico in bronzo, Bronzo - 1 filetto



RBG

Ruota, Rivestimento in gomma - nucleo in polipropilene




TK

Manicotto a sfere autoallineante Topball, Autoallineante,



RDS

Rondella di sicurezza Hygienic Usit®, Inox

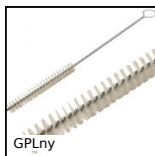


GPLny

Scovolo, nylon



ACLEFS

Elementi di ancoraggio,

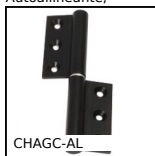

CHAGC-AL

Cerniera ad avvitare, Sfilabile



PW\_PWG2

Vite senza fine di precisione, Inox

**Prodotti correlati**