

Fixed cylindrical handle

PCM

Black Duroplast

- Fixed non-turning handle

- Material:

Black Duroplast


Advantages

- Good grip

- Easier to clean than technopolymer alternatives

- No retention of swarf in a machining environment.

Good resistance

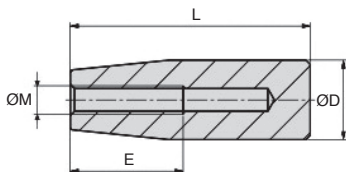

DISCOUNTS

Qty	1+	6+	20+	50+	100+	250+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	ØM	ØD	L	E	Weight (g)	Stock*	Price each 1 to 5
PCM5-13-27	M5	13	27	14	4	✓	2,40 €
PCM6-13-27	M6	13	27	14	4	-	2,40 €
PCM6-17-40	M6	17	40	20	9	✓	2,40 €
PCM8-17-40	M8	17	40	25	8	✓	2,40 €
PCM6-21-50	M6	21	50	25	20	✓	2,99 €
PCM8-21-50	M8	21	50	25	19	-	2,99 €
PCM10-21-50	M10	21	50	25	18	✓	2,99 €
PCM6-23-55	M6	23	55	25	25	-	3,27 €
PCM8-23-55	M8	23	55	25	24	-	3,27 €
PCM10-23-55	M10	23	55	25	24	-	3,27 €
PCM8-25-65	M8	25	65	30	36	✓	3,48 €
PCM10-25-65	M10	25	65	30	35	✓	3,48 €
PCM12-25-65	M12	25	65	30	34	✓	3,48 €
PCM8-28-85	M8	28	85	40	61	✓	4,52 €
PCM10-28-85	M10	28	85	40	59	-	4,52 €
PCM12-28-85	M12	28	85	40	56	-	4,52 €
PCM14-28-85	M14	28	85	40	52	✓	4,52 €
PCM8-29-115	M8	29	115	40	92	-	7,76 €
PCM10-29-115	M10	29	115	40	88	✓	7,76 €
PCM12-29-115	M12	29	115	40	84	✓	7,76 €

Dimensions in mm

Altri prodotti...



ACL-FPA
Accessori per pannelli,
Morsetto angolare



BAC110
Contenitore a becco,
Aggancio orientabile



PRES
Accessori per pressa
PRES-3HR e
PRES-4HR, Portapinzine




RPCtc
Ruota girevole a foro
centrale, Acciaio -
Poliammide - a doppio
bloc...



CFF_SS
Testa a snodo
femmina DIN
ISO12240-4, Inox /
bronzo - Serie




CHCSS
Vite a testa cava
esagonale CHC, Inox -
A2

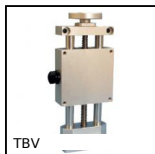

TBV
Tavola di
posizionamento
verticale manuale,
3kg



AFA
Perno di fissaggio, con
anello

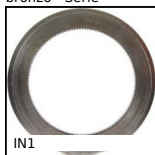

IN1
Ingranaggio interno,
Acciaio 20NCD2



VPSS
Volantino a 6 lobi,
Duroplast - Inox



H3
Ingranaggio elicoidale
ad assi incrociati a
90°, Acciaio 20NCD2



TBD
Tavola di
posizionamento a
passo inverso
manuale, 40kg

Prodotti correlati



LPCM
Leva con impugnatura
cilindrica, Duroplast
nero, leva in acciaio