

Fixed cylindrical handle

PCM

Black Duroplast

- Fixed non-turning handle

- Material:

Black Duroplast


Advantages

- Good grip

- Easier to clean than technopolymer alternatives

- No retention of swarf in a machining environment.

Good resistance

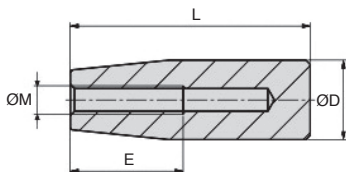

DISCOUNTS

| Qty | 1+ | 6+ | 20+ | 50+ | 100+ | 250+ |
|-------|------|-----|------|------|------|------------|
| Disc. | List | -5% | -10% | -15% | -20% | On request |

| Part number | ØM | ØD | L | E | Weight (g) | Stock* | Price each 1 to 5 |
|--------------|-----|----|-----|----|------------|--------|-------------------|
| PCM5-13-27 | M5 | 13 | 27 | 14 | 4 | ✓ | 2,40 € |
| PCM6-13-27 | M6 | 13 | 27 | 14 | 4 | - | 2,40 € |
| PCM6-17-40 | M6 | 17 | 40 | 20 | 9 | ✓ | 2,40 € |
| PCM8-17-40 | M8 | 17 | 40 | 25 | 8 | ✓ | 2,40 € |
| PCM6-21-50 | M6 | 21 | 50 | 25 | 20 | ✓ | 2,99 € |
| PCM8-21-50 | M8 | 21 | 50 | 25 | 19 | - | 2,99 € |
| PCM10-21-50 | M10 | 21 | 50 | 25 | 18 | ✓ | 2,99 € |
| PCM6-23-55 | M6 | 23 | 55 | 25 | 25 | - | 3,27 € |
| PCM8-23-55 | M8 | 23 | 55 | 25 | 24 | - | 3,27 € |
| PCM10-23-55 | M10 | 23 | 55 | 25 | 24 | - | 3,27 € |
| PCM8-25-65 | M8 | 25 | 65 | 30 | 36 | ✓ | 3,48 € |
| PCM10-25-65 | M10 | 25 | 65 | 30 | 35 | ✓ | 3,48 € |
| PCM12-25-65 | M12 | 25 | 65 | 30 | 34 | ✓ | 3,48 € |
| PCM8-28-85 | M8 | 28 | 85 | 40 | 61 | ✓ | 4,52 € |
| PCM10-28-85 | M10 | 28 | 85 | 40 | 59 | - | 4,52 € |
| PCM12-28-85 | M12 | 28 | 85 | 40 | 56 | - | 4,52 € |
| PCM14-28-85 | M14 | 28 | 85 | 40 | 52 | ✓ | 4,52 € |
| PCM8-29-115 | M8 | 29 | 115 | 40 | 92 | - | 7,76 € |
| PCM10-29-115 | M10 | 29 | 115 | 40 | 88 | ✓ | 7,76 € |
| PCM12-29-115 | M12 | 29 | 115 | 40 | 84 | ✓ | 7,76 € |

Dimensions in mm

Altri prodotti...



LRR-53

Chiavistello con bloccaggio, Lucchetto a molla acciaio



RAG-12-M8

Guida di scorrimento a rotelle, Sistema di ancoraggio



GG1

Ingranaggio dritto rettificato, Acciaio trattato



GARQT

Perno di bloccaggio tipo ¼ di giro, ¼ di giro



SCE

Serracavo, Acciaio



DOG316

Motoriduttore DC 12V e 24V DC, da 1.5 a 2 Nm



SVT_CH

Martinetto a vite - Montaggio con terminale forato, Console girevole



PRF-SCREEN-4

Screen support, Support with 4 axes of rotation



NPTF20

Morsetto di collegamento, Fisso



SVT15

Martinetto a vite - Vite traslante, Vite



PRF_GAL

Rotella per profilo alluminio, Kit di



RFK28B

Riduttore ipoide inox, fino a 130 Nm

Prodotti correlati



LPCM

Leva con impugnatura cilindrica, Duroplast nero, leva in acciaio