

# Fixed cylindrical handle

## PCM

## Black Duroplast

- Fixed non-turning handle

- Material:

Black Duroplast


### Advantages

- Good grip

- Easier to clean than technopolymer alternatives

- No retention of swarf in a machining environment.

Good resistance

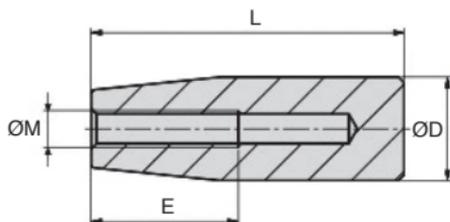

### DISCOUNTS

Qty	1+	6+	20+	50+	100+	250+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	ØM	ØD	L	E	Weight (g)	Stock*	Price each 1 to 5
PCM5-13-27	M5	13	27	14	4	✓	2,40 €
PCM6-13-27	M6	13	27	14	4	-	2,40 €
PCM6-17-40	M6	17	40	20	9	✓	2,40 €
PCM8-17-40	M8	17	40	25	8	✓	2,40 €
PCM6-21-50	M6	21	50	25	20	✓	2,99 €
PCM8-21-50	M8	21	50	25	19	-	2,99 €
PCM10-21-50	M10	21	50	25	18	✓	2,99 €
PCM6-23-55	M6	23	55	25	25	-	3,27 €
PCM8-23-55	M8	23	55	25	24	-	3,27 €
PCM10-23-55	M10	23	55	25	24	-	3,27 €
PCM8-25-65	M8	25	65	30	36	✓	3,48 €
PCM10-25-65	M10	25	65	30	35	✓	3,48 €
PCM12-25-65	M12	25	65	30	34	✓	3,48 €
PCM8-28-85	M8	28	85	40	61	✓	4,52 €
PCM10-28-85	M10	28	85	40	59	-	4,52 €
PCM12-28-85	M12	28	85	40	56	-	4,52 €
PCM14-28-85	M14	28	85	40	52	✓	4,52 €
PCM8-29-115	M8	29	115	40	92	-	7,76 €
PCM10-29-115	M10	29	115	40	88	✓	7,76 €
PCM12-29-115	M12	29	115	40	84	✓	7,76 €

Dimensions in mm

## Altri prodotti...



HTD14M\_55

Puleggia dentata di trasmissione tipo HTD, HTD14 Ghisa



VCMB

Vite di giunzione metallo/legno, Acciaio



GMK17\_BR

Morsetto porta guide, Conico doppio



PSPD40

Manopola a pressione, PVC nero



NCT

Giunto di collegamento, Ad angolo fisso



BOXdh

Box kit di spine cilindriche DIN6325, Box kit - standard DIN 6325



RTE

Rotex®, elastico, Alluminio



RT25

Calettatore di bloccaggio, Coppia media/elevata



PSG25

Ingranaggio dritto di precisione, Acciaio 20NCd2 cementato



ACLERP

Rulliera, Con guida laterale



GE\_ET\_2RS

Snodo sferico, Cromo duro/PTFE con guarnizioni di tenuta



JCSs

Giunto cardanico - inox, Sollecitazioni leggere

## Prodotti correlati



LPCM

Leva con impugnatura cilindrica, Duroplast nero, leva in acciaio