


## C45 steel

## Pitch 6mm

- Pitch 6mm (DIN 04-1)
- Roller diameter 4mm
- Material:  
C45 UNI7845 steel
- HPC are unable to modify these parts
- \*\*The prebore dimensions are given as a guide only and are subject to change

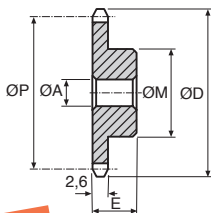

### Accessories

- Chain part number SUA-6/M

**Economy range**

### DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-12%	-25%	On request

Part number	Z teeth	ØP	ØD	ØM	ØA**	E	Weight (kg)	Price each
PCS6-10	10	19,42	21,70	13	6	10	0,01	1,37 €
PCS6-11	11	21,30	23,60	14	6	10	0,01	1,47 €
PCS6-12	12	23,18	25,40	16	6	10	0,02	2,14 €
PCS6-13	13	25,05	27,30	18	8	10	0,02	2,48 €
PCS6-14	14	26,96	29,20	20	8	10	0,03	2,48 €
PCS6-15	15	28,86	31,00	20	8	10	0,03	2,48 €
PCS6-16	16	30,76	33,00	20	8	13	0,03	2,86 €
PCS6-17	17	32,65	35,00	20	8	13	0,04	3,40 €
PCS6-18	18	34,55	36,90	20	8	13	0,04	3,40 €
PCS6-19	19	36,44	38,80	20	8	13	0,04	3,48 €
PCS6-20	20	38,34	40,70	20	8	13	0,04	3,61 €
PCS6-21	21	40,25	42,60	25	8	13	0,06	3,91 €
PCS6-22	22	42,16	44,50	25	8	13	0,06	4,33 €
PCS6-23	23	44,06	46,40	25	8	13	0,06	4,53 €
PCS6-24	24	45,96	48,30	25	8	13	0,07	4,62 €
PCS6-25	25	47,87	50,20	25	8	13	0,07	5,30 €
PCS6-27	27	51,67	54,00	30	8	15	0,10	5,80 €
PCS6-30	30	57,42	59,80	30	8	15	0,11	7,49 €
PCS6-33	33	63,11	65,50	30	8	15	0,12	8,12 €
PCS6-35	35	66,93	69,30	30	8	15	0,13	8,28 €
PCS6-36	36	68,84	71,20	30	8	15	0,13	8,96 €
PCS6-38	38	72,66	75,00	30	8	15	0,14	9,34 €
PCS6-40	40	76,47	78,90	30	8	15	0,15	10,31 €
PCS6-45	45	86,01	88,50	40	10	16	0,46	12,83 €
PCS6-48	48	91,74	94,20	62	12	18	0,48	13,25 €
PCS6-50	50	95,55	98,00	50	12	20	0,49	13,42 €
PCS6-57	57	108,93	111,40	50	12	20	0,53	14,14 €
PCS6-76	76	145,19	147,60	60	12	20	1,58	29,25 €

Dimensions in mm

0 825 88 6000

Service 0,15 € / min  
+ prix appel

Fax

## Altri prodotti...



ACM\_AZ

Aggancio per tirante  
chiusura in gomma,  
Aggancio



PLM-20SC

Magnete cilindrico,  
Magnete cilindrico



DB

Ingranaggio conico -  
Acciaio 60C40, 2:1



KK

Chiavetta  
rettangolare, Acciaio



DBL820

Rotella per catena,  
Serie 820 e 815



LRR22

Small dimension latch  
with locking system,  
Aluminium



ACL-FPA

Accessori per pannelli,  
Morsetto angolare



PRF\_ECL

Fissaggio, Dado  
quadrato con  
linguetta - Inox



WINGbrEcrou

Dado ad alette per  
serraggio manuale



LACM\_SS

Leva a camma inox,  
Femmina



BTESS

Tenditore automatico  
universale per



PSG3S

Ingranaggio dritto di  
precisione, Inox 316

## Prodotti correlati



SUA4

Catena semplice al  
metro, Acciaio



SUA4\_L

Giunzione per catena  
al metro, Maglia di  
giunzione - acciaio