

Pitch  
**8mm** C45 steel



- Pitch 8mm (DIN 05B-1)
- Roller diameter 5mm
- Material:

C45 UNI7845 steel


- HPC are unable to modify these parts

-\*\*The prebore dimensions are given as a guide only and are subject to change

## Accessories

- Chain part number SBR-8/M, SBS-8/M

**Economy range**

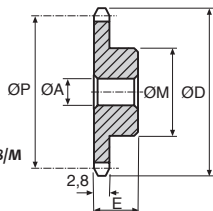

## DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-12%	-25%	On request

Part number	Z teeth	ØP	ØD	ØM	ØA**	E	Weight (kg)	Price each
PCS8-8	8	20,90	24,0	13	6	12	0,01	1,25 €
PCS8-9	9	23,39	26,6	15	6	12	0,02	1,29 €
PCS8-10	10	25,89	29,2	17	8	12	0,02	1,37 €
PCS8-11	11	28,39	31,7	18	8	13	0,03	1,47 €
PCS8-12	12	30,91	34,2	20	8	13	0,04	2,14 €
PCS8-13	13	33,42	36,7	23	8	13	0,05	2,22 €
PCS8-14	14	35,95	39,2	25	8	13	0,05	2,48 €
PCS8-15	15	38,48	41,7	28	8	13	0,07	2,76 €
PCS8-16	16	41,01	44,3	30	8	14	0,08	3,02 €
PCS8-17	17	43,53	46,8	30	8	14	0,09	3,02 €
PCS8-18	18	46,07	49,3	30	8	14	0,09	3,36 €
PCS8-19	19	48,61	51,9	30	8	14	0,09	3,57 €
PCS8-20	20	51,14	54,4	30	8	14	0,10	3,69 €
PCS8-21	21	53,68	57,0	35	8	14	0,12	4,33 €
PCS8-23	23	58,75	62,0	35	8	14	0,13	4,58 €
PCS8-25	25	63,83	67,5	35	8	14	0,15	5,08 €
PCS8-27	27	68,91	72,2	40	10	16	0,20	5,34 €
PCS8-30	30	76,53	79,8	40	10	16	0,22	6,35 €
PCS8-33	33	84,16	87,5	40	10	16	0,24	7,23 €
PCS8-35	35	89,25	92,5	40	10	16	0,25	8,20 €
PCS8-36	36	91,79	95,0	40	10	16	0,26	8,96 €
PCS8-38	38	96,88	100,2	40	10	16	0,28	9,00 €
PCS8-39	39	99,42	102,7	40	10	16	0,29	9,13 €
PCS8-40	40	101,97	105,3	40	10	16	0,58	10,52 €
PCS8-45	45	114,69	118,0	60	12	20	0,67	14,73 €
PCS8-48	48	122,32	125,6	60	12	20	0,63	16,37 €
PCS8-50	50	127,41	130,7	60	12	20	1,00	17,04 €

Dimensions in mm

## Altri prodotti...



RPP  
Piastra di giunzione  
per cinghia RPP, RPP5



SHW  
Rondella semplice,  
Inox A2




VBFP  
Volantino a 6 lobi -  
boccola passante,  
Duroplast - Inox



SHNbr  
Dado esagonale -  
DIN934, Ottone



PTAF80-PAMF80  
Piede fissabile con  
base lamiera Ø80, Ø  
80

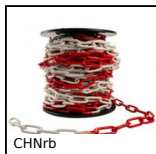

CHNrb  
Catena segnaletica  
rossa e bianca,  
Acciaio




DOMI80  
Accessori di  
collegamento, Kit di  
fissaggio



HG5  
Ingranaggio dritto  
acciaio, Acciaio  
20NCD2



KB\_OP  
Manicotto a sfere di  
precisione, Di  
precisione - acciaio

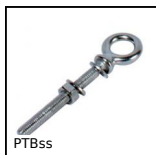

PTBss  
Bullone a occhiello  
inox, Inox



CHT  
Motore AC asincrono  
trifase, 0.18 a 0.55kW



PX  
Riduttore a ruota e  
vite senza fine, Albero  
semplice in uscita per  
r...

## Prodotti correlati



SUA4  
Catena semplice al  
metro, Acciaio



SUA4\_L  
Giunzione per catena  
al metro, Maglia di  
giunzione - acciaio