

Pitch
8mm C45 steel




Economy range

- Pitch 8mm (DIN 05B-1)
- Roller diameter 5mm
- Material:

C45 UNI7845 steel

- HPC are unable to modify these parts

-**The prebore dimensions are given as a guide only and are subject to change

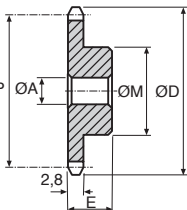

Accessories

- Chain part number SBR-8/M, SBS-8/M

DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-12%	-25%	On request

Part number	Z teeth	OP	OD	OM	OA**	E	Weight (kg)	Price each
PCS8-8	8	20,90	24,0	13	6	12	0,01	1,25 €
PCS8-9	9	23,39	26,6	15	6	12	0,02	1,29 €
PCS8-10	10	25,89	29,2	17	8	12	0,02	1,37 €
PCS8-11	11	28,39	31,7	18	8	13	0,03	1,47 €
PCS8-12	12	30,91	34,2	20	8	13	0,04	2,14 €
PCS8-13	13	33,42	36,7	23	8	13	0,05	2,22 €
PCS8-14	14	35,95	39,2	25	8	13	0,05	2,48 €
PCS8-15	15	38,48	41,7	28	8	13	0,07	2,76 €
PCS8-16	16	41,01	44,3	30	8	14	0,08	3,02 €
PCS8-17	17	43,53	46,8	30	8	14	0,09	3,02 €
PCS8-18	18	46,07	49,3	30	8	14	0,09	3,36 €
PCS8-19	19	48,61	51,9	30	8	14	0,09	3,57 €
PCS8-20	20	51,14	54,4	30	8	14	0,10	3,69 €
PCS8-21	21	53,68	57,0	35	8	14	0,12	4,33 €
PCS8-23	23	58,75	62,0	35	8	14	0,13	4,58 €
PCS8-25	25	63,83	67,5	35	8	14	0,15	5,08 €
PCS8-27	27	68,91	72,2	40	10	16	0,20	5,34 €
PCS8-30	30	76,53	79,8	40	10	16	0,22	6,35 €
PCS8-33	33	84,16	87,5	40	10	16	0,24	7,23 €
PCS8-35	35	89,25	92,5	40	10	16	0,25	8,20 €
PCS8-36	36	91,79	95,0	40	10	16	0,26	8,96 €
PCS8-38	38	96,88	100,2	40	10	16	0,28	9,00 €
PCS8-39	39	99,42	102,7	40	10	16	0,29	9,13 €
PCS8-40	40	101,97	105,3	40	10	16	0,58	10,52 €
PCS8-45	45	114,69	118,0	60	12	20	0,67	14,73 €
PCS8-48	48	122,32	125,6	60	12	20	0,63	16,37 €
PCS8-50	50	127,41	130,7	60	12	20	1,00	17,04 €

Dimensions in mm

Altri prodotti...



RPP

Piastra di giunzione per cinghia RPP, RPP14



ZBconique

Ingranaggio conico in plastica, 1:1



HCV

Sistema di guida su binario a V Simple Select®, con carrello




Q6

Cuscinetto radiale a sfere, Acciaio



OP3_14_06

Accessorio per indicatori, Boccola di riduzione

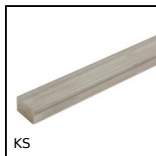


KS

Chiavetta in barre, Inox - in barre



RBNTc

Ruota girevole a foro centrale, Acciaio - caucciù - a doppio blocca...

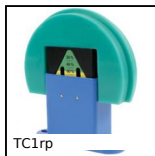

TC1rp

Tenditore per catena automatico, Con pattino 180°



PRF_GAL

Rotella per profilo alluminio, Rotella liscia




CLG2

Ingranaggio dritto in plastica stampata, Nylon stampato



ACLERP

Rulliera, Con guida laterale

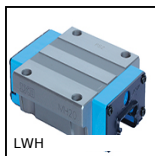

LWH

Guida lineare a sfere - Sfere acciaio, Carello - da 9320 N a 71300 N

Prodotti correlati



SUA4

Catena semplice al metro, Acciaio



SUA4_L

Giunzione per catena al metro, Maglia di giunzione - acciaio