

Detectable plastic palm grip

New

PDM Thermoplastic identifiable by metal detectors

- **Operating element for sensitive sectors**
- In the event of breakage during production in sensitive sectors such as the food industry, the plastic fragments are easily identified by metal detectors, enabling them to be disposed of quickly
- Material :
 - Detectable thermoplastic (glass-fibre reinforced polyamide), EU10/2011 and FDA compliant (colour RAL7021)
 - Components in polished 316L stainless steel
- Operating temperature: -20°C to +100°C






NEW !

Application

- Food industry
- Pharmaceutical industry
- Packaging industry

Info.

- Metal detectable plastic
- Detection volume $\geq 0.027 \text{ cm}^3$
- Food-grade materials

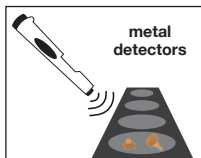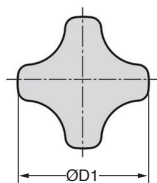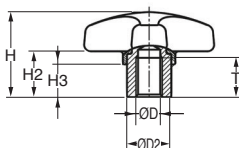

Typical application

DISCOUNTS

Qty	1+	6+	10+	25+
Disc.	List	-5%	-10%	On request

Part Number	ØD	ØD1	ØD2	H	H2	H3	T	Price each
								1 to 5
PDM25-5	M5	25	10,0	18	9	7,0	9	10,88 €
PDM32-6	M6	32	13,5	22	12	9,5	12	13,24 €
PDM40-6	M6	40	13,5	26	14	10,0	12	16,51 €
PDM40-8	M8	40	13,5	26	14	10,0	12	16,51 €
PDM50-8	M8	50	19,0	32	18	12,0	17	22,45 €
PDM50-10	M10	50	19,0	32	18	12,0	17	22,45 €


Dimensions in mm

New

Detectable plastic palm grip

Thermoplastic identifiable by metal detectors PDM

- **Operating element for sensitive sectors**
- In the event of breakage during production in sensitive sectors such as the food industry, the plastic fragments are easily identified by metal detectors, enabling them to be disposed of quickly
- Material :
 - Detectable thermoplastic (glass-fibre reinforced polyamide), EU10/2011 and FDA compliant (colour RAL7021)
 - Components in polished 316L stainless steel
- Operating temperature: -20°C to +100°C

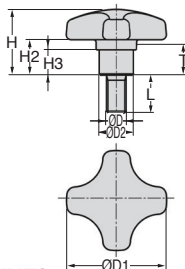
NEW !

Application

- Food industry
- Pharmaceutical industry
- Packaging industry

Info.

- Metal detectable plastic
- Detection volume $\geq 0.027 \text{ cm}^3$
- Food-grade materials

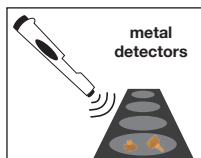**Typical application**

DISCOUNTS

Qty	1+	6+	10+	25+
Disc.	List	-5%	-10%	On request

Part Number	ØD	ØD1	ØD2	H	H2	H3	L	Price each
								1 to 5
PDM25-5-10	M5	25	10	18	9	7	10	11,24 €
PDM25-5-15	M5	25	10	18	9	7	15	11,24 €
PDM25-5-20	M5	25	10	18	9	7	20	11,24 €
PDM32-6-10	M6	32	13,5	22	12	9,5	10	12,27 €
PDM32-6-15	M6	32	13,5	22	12	9,5	15	12,27 €
PDM32-6-20	M6	32	13,5	22	12	9,5	20	12,27 €
PDM32-6-25	M6	32	13,5	22	12	9,5	25	12,94 €
PDM32-6-30	M6	32	13,5	22	12	9,5	30	12,94 €
PDM40-8-15	M8	40	13,5	26	14	10	15	15,39 €
PDM40-8-20	M8	40	13,5	26	14	10	20	15,82 €
PDM40-8-25	M8	40	13,5	26	14	10	25	16,15 €
PDM40-8-30	M8	40	13,5	26	14	10	30	16,45 €
PDM40-8-40	M8	40	13,5	26	14	10	40	17,21 €
PDM40-8-50	M8	40	13,5	26	14	10	50	17,57 €
PDM50-10-20	M10	50	19	32	18	12	20	20,69 €
PDM50-10-25	M10	50	19	32	18	12	25	20,97 €
PDM50-10-30	M10	50	19	32	18	12	30	21,33 €
PDM50-10-40	M10	50	19	32	18	12	40	21,79 €
PDM50-10-50	M10	50	19	32	18	12	50	22,09 €
PDM50-10-60	M10	50	19	32	18	12	60	22,45 €

Dimensions in mm

Detectable plastic palm grip

New

PDV **Visually identifiable** blue thermoplastic

- Ultramarine blue operating element for sensitive sectors
- In the event of breakage during production in sensitive sectors such as the food industry, plastic fragments are easily identified visually, enabling them to be removed quickly
- Materials :
Visually detectable thermoplastic (glass-fibre reinforced polyamide), EU10/2011 and FDA compliant (RAL5002 colour)
Components in polished 316L stainless steel
- Operating temperature: -20°C to +100°C



NEW !

Application



- Food industry
- Pharmaceutical industry
- Packaging industry

Info.

- Food-grade materials



Typical application

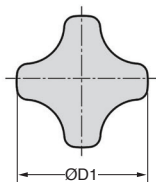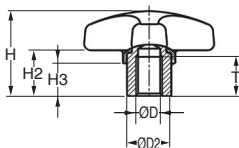

DISCOUNTS

Qty	1+	6+	10+	25+
Disc.	List	-5%	-10%	On request

Part Number	ØD	ØD1	ØD2	H	H2	H3	T	Price each
								1 to 5
PDV25-5	M5	25	10	18	9	7	9	10,15 €
PDV32-6	M6	32	13,5	22	12	9,5	12	12,36 €
PDV40-6	M6	40	13,5	26	14	10	12	15,45 €
PDV40-8	M8	40	13,5	26	14	10	12	15,45 €
PDV50-8	M8	50	19	32	18	12	17	20,94 €
PDV50-10	M10	50	19	32	18	12	17	20,94 €


Dimensions in mm

New

Detectable plastic palm grip

Visually identifiable blue thermoplastic PDV**NEW!**

- Ultramarine blue operating element for sensitive sectors
- In the event of breakage during production in sensitive sectors such as the food industry, plastic fragments are easily identified visually, enabling them to be removed quickly
- Materials :
Visually detectable thermoplastic (glass-fibre reinforced polyamide), EU10/2011 and FDA compliant (RAL5002 colour)
Components in polished 316L stainless steel
- Operating temperature: -20°C to +100°C

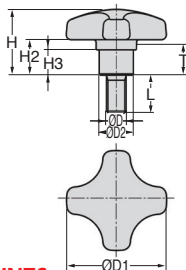

Application

- Food industry
- Pharmaceutical industry
- Packaging industry

Info.

- Food-grade materials

**Typical application**


DISCOUNTS

Qty	1+	6+	10+	25+
Disc. List	-5%	-10%	On request	

Part Number	ØD	ØD1	ØD2	H	H2	H3	L	Price each
								1 to 5
PDV25-5-10	M5	25	10,0	18	9	7,0	10	10,51 €
PDV25-5-15	M5	25	10,0	18	9	7,0	15	10,51 €
PDV25-5-20	M5	25	10,0	18	9	7,0	20	10,51 €
PDV32-6-10	M6	32	13,5	22	12	9,5	10	11,42 €
PDV32-6-15	M6	32	13,5	22	12	9,5	15	11,42 €
PDV32-6-20	M6	32	13,5	22	12	9,5	20	11,42 €
PDV32-6-25	M6	32	13,5	22	12	9,5	25	12,06 €
PDV32-6-30	M6	32	13,5	22	12	9,5	30	12,06 €
PDV40-8-15	M8	40	13,5	26	14	10,0	15	14,36 €
PDV40-8-20	M8	40	13,5	26	14	10,0	20	14,76 €
PDV40-8-25	M8	40	13,5	26	14	10,0	25	15,06 €
PDV40-8-30	M8	40	13,5	26	14	10,0	30	15,39 €
PDV40-8-40	M8	40	13,5	26	14	10,0	40	16,03 €
PDV40-8-50	M8	40	13,5	26	14	10,0	50	16,36 €
PDV50-10-20	M10	50	19,0	32	18	12,0	20	19,33 €
PDV50-10-25	M10	50	19,0	32	18	12,0	25	19,54 €
PDV50-10-30	M10	50	19,0	32	18	12,0	30	19,91 €
PDV50-10-40	M10	50	19,0	32	18	12,0	40	20,33 €
PDV50-10-50	M10	50	19,0	32	18	12,0	50	20,60 €
PDV50-10-60	M10	50	19,0	32	18	12,0	60	20,94 €

Dimensions in mm

Altri prodotti...

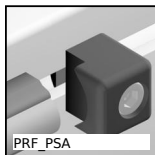

PRF_PSA
Rotella per profilo
alluminio, per
bloccaggio albero



MAX26
Motoriduttore DC 12V
e 24V DC, da 0,075 a
0,6Nm



ACLBT5
Sistema di chiusura
per profili alluminio,
Spessore per blocca
porta...



MPS
Distanziatore
esagonale, Inox 303



BTESS
Tenditore automatico
universale per
tenditore, Per
ambienti aggressivi



DOMI120
Accessori di
collegamento, Piatto
girevole




NDS20
Connettore di
serraggio, Parallela



MFBS
Giunto a soffietto
Inox, Inox - con vite a
pressione



CM
Attrezzi Hygienic
Usit® and Hygienic

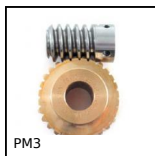

PM3
Coppia ruota e vite
senza fine, Bronzo



BPP
Supporto ritto in
lamiera con



NK27
Guida mini Drylin® N,
Larghezza 27 mm

Prodotti correlati



BEAS
Manopola, stella,
antistatico



BEAS
Star shaped anti-
static handle, Star,
anti-static



BEAB
Manopola, stella, anti-
batterial



BEAB
Manopola, stella,
antibatterico