

Mounting feet with integrated castors

Offset castor

PDR


- Combines the advantages of a static mounting foot and a castor
- Use a hexagonal spanner to release the castor
- Castor protrudes 12.5mm when released
- Only for use on surfaces that are smooth (crevices less than 5mm) and horizontal (max slope 3°)
- Max static load 2,500 kg per foot
- Max load 200 kg per foot if used in movable mode
- Materials:
 - Base - Polyamide
 - Sole - NBR rubber
 - Threaded shaft - Chromed steel

Typical application


- A vessel remains static whilst the product within is processed but once empty, can be moved for cleaning purposes.

Advantages

- Flexibility (1 item performs 2 functions)
- Less manoeuvring to move a structure
- Time saving

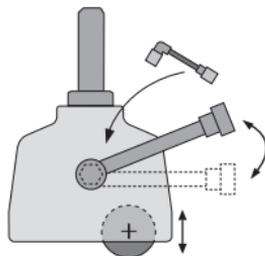

Retracting the castor

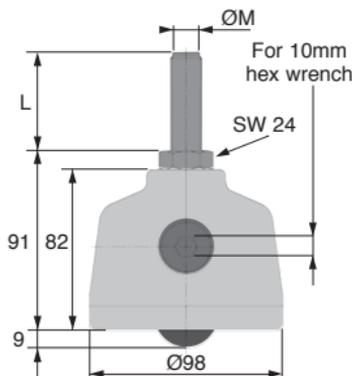

DISCOUNTS

Qty	1+	6+	10+
Disc.	List	-5%	On request

Part number	ØM	L	Load Castor fixed (static) (kg)	Load Castor free (dynamic) (kg)	Price each 1 to 5
With threaded shaft					
PDR100-16-50/RD	M16	50	2500	200	118,60 €
PDR100-16-100/RD	M16	100	2500	200	122,18 €
PDR100-20-75/RD	M20	75	2500	200	122,18 €
PDR100-20-125/RD	M20	125	2500	200	125,78 €
PDR100-24-75/RD	M24	75	2500	200	122,18 €
PDR100-24-125/RD	M24	125	2500	200	125,78 €
With 80x80mm mounting plate					
PDR100-80-80/RD	4x8.5mm holes		2500	200	122,18 €

Dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

Altri prodotti...



NTMdl

Grano punta in delrin,
punta in delrin



SCA

Serracavo, Acciaio



MEF

Cuscinetto cilindrico,
Lega di ferro FP20
autolubrificante
METAFRAM



VPR

Vite ad alette
Hygienic Usit®, Inox



TK_UUOP

Manicotto a sfere
autoallineante
Topball,
Autoallineante Topball



CHA35

Cerniera ad avvitare,
Hinge



UTKpwr

Guida lineare
Utilitrack®, Profilo
guida a V



TM_CTM_CTF

Accessori per ventosa,
Inserto per ventosa -
A scatto



PRF4590_E

Squadra di giunzione,
PRF4590



BABTV

Ball lock pins lockable
, Stainless steel



RPCtc

Ruota girevole a foro
centrale, Acciaio -
Poliamide



AC144

Piastrina di riscontro
piatta per chiusura,
22mm

Prodotti correlati



RIMtce

Ruota di livellamento,
Con foro centrale



RIMple

Ruota di livellamento,
Con piastra