

Mounting feet with integrated castors

Offset castor

PDR


- Combines the advantages of a static mounting foot and a castor
- Use a hexagonal spanner to release the castor
- Castor protrudes 12.5mm when released
- Only for use on surfaces that are smooth (crevices less than 5mm) and horizontal (max slope 3°)
- Max static load 2,500 kg per foot
- Max load 200 kg per foot if used in movable mode
- Materials:
 - Base - Polyamide
 - Sole - NBR rubber
 - Threaded shaft - Chromed steel

Typical application


- A vessel remains static whilst the product within is processed but once empty, can be moved for cleaning purposes.

Advantages

- Flexibility (1 item performs 2 functions)
- Less manoeuvring to move a structure
- Time saving

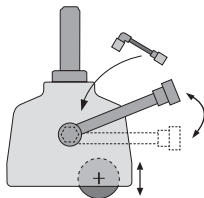

Retracting the castor

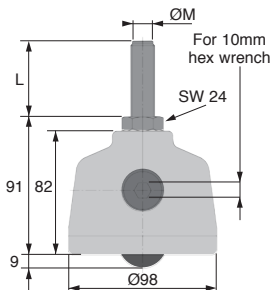

DISCOUNTS

Qty	1+	6+	10+
Disc.	List	-5%	On request

Part number	ØM	L	Load Castor fixed (static) (kg)	Load Castor free (dynamic) (kg)	Price each 1 to 5
With threaded shaft					
PDR100-16-50/RD	M16	50	2500	200	118,60 €
PDR100-16-100/RD	M16	100	2500	200	122,18 €
PDR100-20-75/RD	M20	75	2500	200	122,18 €
PDR100-20-125/RD	M20	125	2500	200	125,78 €
PDR100-24-75/RD	M24	75	2500	200	122,18 €
PDR100-24-125/RD	M24	125	2500	200	125,78 €
With 80x80mm mounting plate					
PDR100-80-80/RD	4x8.5mm holes		2500	200	122,18 €

Dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

Fax


cial2@hpceurope.com

HPC

SUPPLEMENT 2019

281

Altri prodotti...

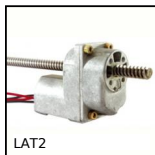

LAT2

Attuatore lineare a motore 2A, 2 ampere



BCM_HPBT

Spazzola cilindrica modulare, Filo poliester PBT



VQT

Chiusura ¼ di giro per bloccaggio , Manopola plastica o inox



GALRUB

Rullo per trasportatore, Caucciù



FAD

Piede snodato semplice, Piede inclinabile senza suola antiscivolo



KSM

Dado cilindrico in acciaio, Acciaio - 1 filetto




BEAB

Manopola, stella, anti-bacterial



SVT30

Martinetto a vite - Vite traslante, Vite traslante

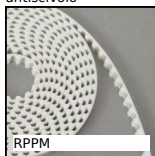

RPPM

Cinghia aperta al metro tipo RPP, RPP8 Poliuretano armatura in acciaio



SBF

Sealed flange bearing unit for Food Industry, cover



T10_30_AL

Puleggia dentata di posizionamento tipo T, Serie economica - T10 all...



CHML63

Riduttore a ruota e vite senza fine, fino a 138 Nm - Con limitatore ...

Prodotti correlati



RIMtce

Ruota di livellamento, Con foro centrale



RIMple

Ruota di livellamento, Con piastra